


Product data sheet

Specifications

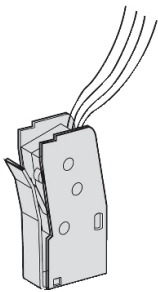

auxiliary contact - 1 OC early-break - for switch NS100...250

29345

! Discontinued

Main

Range Of Product	NS100...250 DC NR100...250 NS100...250 NSF150...250 NS125E
Range	ComPact
Device Short Name	OF
Product Or Component Type	Auxiliary contact
Device Application	Control
Range Compatibility	ComPact ComPact NS circuit breaker ComPact Compact NR circuit breaker ComPact Compact NSF circuit breaker
Signal Contacts Composition	1 NO/NC

Complementary

Auxiliary Contacts Type	Standard
[Ith] Conventional Free Air Thermal Current	6 A
[Ie] Rated Operational Current	AC-12 6 A 110 V AC 50/60 Hz AC-12 6 A 220/240 V AC 50/60 Hz AC-12 6 A 24 V AC 50/60 Hz AC-12 6 A 380/440 V AC 50/60 Hz AC-12 6 A 48 V AC 50/60 Hz AC-12 6 A 480 V AC 50/60 Hz AC-12 6 A 660/690 V AC 50/60 Hz AC-15 0.1 A 660/690 V AC 50/60 Hz AC-15 1.5 A 480 V AC 50/60 Hz AC-15 2 A 380/440 V AC 50/60 Hz AC-15 4 A 220/240 V AC 50/60 Hz AC-15 5 A 110 V AC 50/60 Hz AC-15 6 A 24 V AC 50/60 Hz AC-15 6 A 48 V AC 50/60 Hz DC-12 0.3 A 250 V DC DC-12 0.6 A 110 V DC DC-12 2.5 A 48 V DC DC-12 6 A 24 V DC DC-14 0.03 A 250 V DC DC-14 0.05 A 110 V DC DC-14 0.2 A 48 V DC DC-14 1 A 24 V DC
Minimum Load	100 mA 24 V

Ordering and shipping details

Category	01103-H,J,COMPACT NS UL/IEC CIRCUIT BREAKER ACCESSORIES
Discount Schedule	DE2

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Gtin	3303430293453
Returnability	No

Contractual warranty

Warranty	18 months
----------	-----------