


Product data sheet

Specifications

SQUARE D

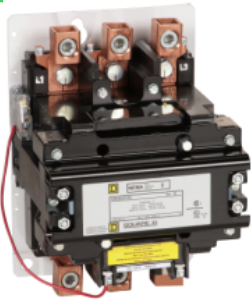

NEMA Contactor, Type S, nonreversing, Size 5, 270A, 200 HP at 575 VAC, 3 phase, up to 100 kA, 3 pole, 120 VAC coil, open

8502SGO2V02S

Product availability : Stock - Normally stocked in distribution facility

Price* : 7,451.00 USD

Main

Product Type	Contactors
Product Range	8502S
Contactors Type	Non-reversing

Complementary

NEMA Size	5
Rated Current	270 A
Number of Poles	3P
Maximum Voltage Rating	600 V AC
Phase	3 phase
Horsepower Rating	75 HP 200 V AC 100 HP 230 V AC 200 HP 460 V AC 200 HP 575 V AC
SCCR	Circuit-breaker 400 A maximum, SCCR: 100 kA at 480 V AC Fuse J 400 A maximum, SCCR: 100 kA at 600 V AC Fuse T 400 A maximum, SCCR: 100 kA at 600 V AC Fuse RK1 400 A maximum, SCCR: 100 kA at 600 V AC Fuse RK5 400 A maximum, SCCR: 100 kA at 600 V AC
Coil Voltage	120 V AC 60 Hz 110 V AC 50 Hz
Control Circuit Type	Separate control circuit
Control Units	No control units
Pilot Light	No indicator
Auxiliary Contacts	Without
Other Equipment	Fuse not supplied
Terminal Type	Screw clamp terminals
Height	12.31 in (312.67 mm)
Width	8.67 in (220.22 mm)
Depth	8.75 in (222.25 mm)

* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Environmental

Enclosure Type	Not rated (open device)
Certifications	UL listed file E78351 CCN NLDX CSA

Ordering and shipping details

Category	21194-8502,36SG(NOT S*R,S*T,S*W)
Discount Schedule	CP1
GTIN	785901851127
Nbr. of units in pkg.	1
Package weight(Lbs)	46.54 lb(US) (21.11 kg)
Returnability	Yes
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	10.31 in (26.2 cm)
Package 1 width	10.98 in (27.9 cm)
Package 1 Length	13.90 in (35.3 cm)

Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Not compliant
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information.

Contractual warranty

Warranty	18 months
----------	-----------