


# Product data sheet

Specifications

SQUARE D

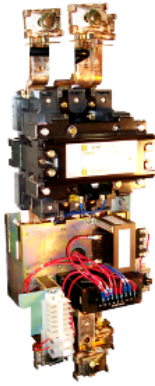

NEMA Contactor, Type S, nonreversing, Size 6, 540A, 400 HP at 575 VAC, 3 phase, up to 100 kA, 3 pole, 120 VAC coil, open

8502SHO2V02S

Product availability : Non-Stock - Not normally stocked in distribution facility

Price\* : 20,339.00 USD

## Main

Product Type	Contactors
Product Range	8502S
Contactors Type	Non-reversing

## Complementary

NEMA Size	6
Rated Current	540 A
Number of Poles	3P
Maximum Voltage Rating	600 V AC
Phase	3 phase
Horsepower Rating	150 HP 200 V AC 200 HP 230 V AC 400 HP 460 V AC 400 HP 575 V AC
SCCR	Circuit-breaker 800 A maximum, SCCR: 65 kA at 480 V AC Fuse J 600 A maximum, SCCR: 100 kA at 600 V AC Fuse T 600 A maximum, SCCR: 100 kA at 600 V AC Fuse RK1 600 A maximum, SCCR: 100 kA at 600 V AC Fuse RK5 600 A maximum, SCCR: 100 kA at 600 V AC
Coil Voltage	120 V AC 60 Hz 110 V AC 50 Hz
Control Circuit Type	Control circuit transformer
Control Units	No control units
Pilot Light	No indicator
Auxiliary Contacts	Without
Other Equipment	2 fuses (primary)
Terminal Type	Screw clamp terminals
Height	28.06 in (712.72 mm)
Width	10.55 in (267.97 mm)
Depth	9.00 in (228.60 mm)

\* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

## Environmental

Enclosure Type	Not rated (open device)
Certifications	UL listed file E78351 CCN NLDX CSA

## Ordering and shipping details

Category	21195 - 8502,36 SH,SJ(NOT S*R,T,W)
Discount Schedule	CP1
GTIN	785901152354
Nbr. of units in pkg.	1
Package weight(Lbs)	74.88 lb(US) (33.965 kg)
Returnability	Yes
Country of origin	MX

## Packing Units

Unit Type of Package 1	PCE
Package 1 Height	13.50 in (34.29 cm)
Package 1 width	12.00 in (30.48 cm)
Package 1 Length	30.50 in (77.47 cm)

## Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Not compliant
China RoHS Regulation	<a href="#">China RoHS declaration</a> Product out of China RoHS scope. Substance declaration for your information.

## Contractual warranty

Warranty	18 months
----------	-----------