


Product data sheet

Specifications

SQUARE D

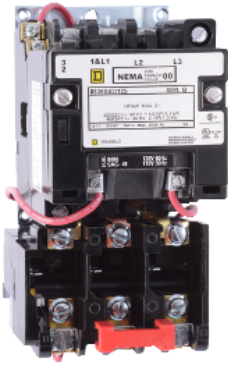

NEMA motor starter, Type S, nonreversing, Size 0, 18A, 5 HP at 460VAC, 5kA SCCR, 3 phase, 3 pole, melting alloy, 240VAC coil, open

8536SBO2V03

Product availability : Stock - Normally stocked in distribution facility

Price* : 485.00 USD

Main

Product Type	Motor starter
Product Range	S
Starter Type	Non reversing

Complementary

NEMA Size	0
Rated Current	18 A
Number of Poles	3P
Maximum Voltage Rating	600 V AC
Phase	3 phase
Type of Overload	Melting alloy 3
Horsepower Rating	3 HP 200 V AC 3 HP 230 V AC 5 HP 460 V AC 5 HP 575 V AC
SCCR	Circuit-breaker: 5 kA at 600 V AC Fuse: 5 kA at 600 V AC
Coil Voltage	220 V AC 50 Hz 240 V AC 60 Hz
Control Circuit Type	Common control circuit
Control Units	No control units
Pilot Light	Without pilot light
Auxiliary Contacts	Without
Terminal Type	Screw clamp terminals
Height	6.81 in (172.96 mm)
Width	3.50 in (88.90 mm)
Depth	4.22 in (107.19 mm)

* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Environment

Enclosure Type Not rated (open device)

Certifications UL Listed
CSA
NEMA

Ordering and shipping details

Category 21191-8502,36 SA,SB(NOT S*R,T,W)

Discount Schedule CP1

GTIN 785901871828

Returnability No

Country of origin MX

Packing Units

Unit Type of Package 1 Db

Number of Units in Package 1 1

Package 1 Height 4.50 in (11.43 cm)

Package 1 Width 5.90 in (14.986 cm)

Package 1 Length 8.00 in (20.32 cm)

Package 1 Weight 4.06 lb(US) (1.842 kg)

Offer Sustainability

California proposition 65 WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

REACH Regulation [REACH Declaration](#)

EU RoHS Directive Not compliant


China RoHS Regulation [China RoHS declaration](#)
Product out of China RoHS scope. Substance declaration for your information.

PVC free Yes

Contractual warranty

Warranty 18 months

Approximate Dimensions

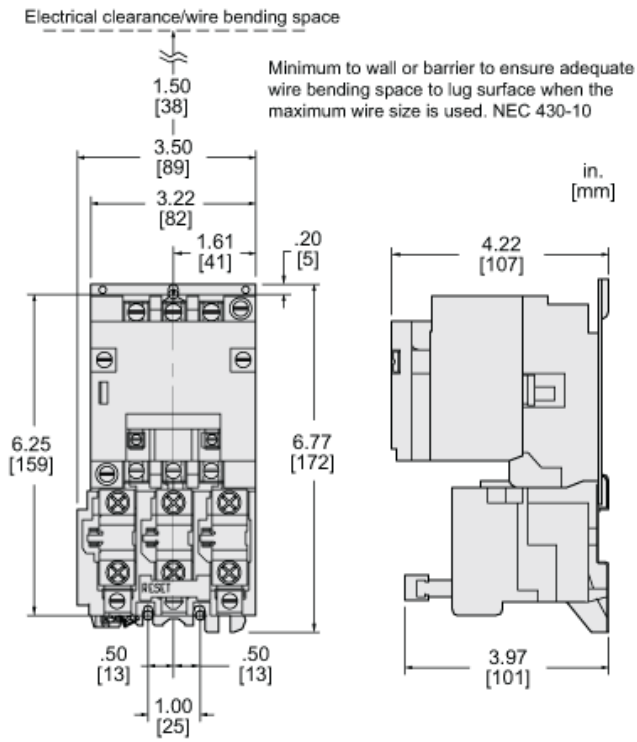

Recommended replacement(s)