


Product data sheet

Specifications

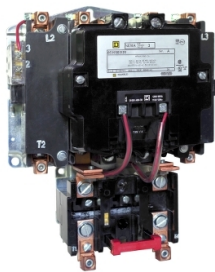

NEMA motor starter, Type S, nonreversing, Size 3, 90A, 50HP at 460VAC, 5kA SCCR, 3 phase, 3 pole, melting alloy, 240VAC coil, open

8536SEO1V03

Product availability: Non-Stock - Not normally stocked in distribution facility

Price*: 1,638.00 USD

Main

| | |
|---------------|---------------|
| Product Type | Motor starter |
| Product Range | S |
| Starter Type | Non reversing |

Complementary

| | |
|------------------------|--|
| Nema Size | 3 |
| Rated Current | 90 A |
| Number Of Poles | 3P |
| Maximum Voltage Rating | 600 V AC |
| Phase | 3 phase |
| Type Of Overload | Melting alloy 3 |
| Horsepower Rating | 25 HP 200 V AC 30 HP 230 V AC 50 HP 460 V AC 50 HP 575 V AC |
| Sccr | Circuit-breaker: 5 kA at 600 V AC Fuse: 5 kA at 600 V AC |
| Coil Voltage | 220 V AC 50 Hz 240 V AC 60 Hz |
| Control Circuit Type | Common control circuit |
| Control Units | No control units |
| Pilot Light | Without pilot light |
| Auxiliary Contacts | Without |
| Terminal Type | Screw clamp terminals |
| Height | 11.09 in (281.69 mm) |
| Width | 5.47 in (138.94 mm) |
| Depth | 6.50 in (165.10 mm) |

Environment

| | |
|----------------|-------------------------|
| Enclosure Type | Not rated (open device) |
|----------------|-------------------------|

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

| | |
|----------------|--------------------------|
| Certifications | UL Listed CSA NEMA |
|----------------|--------------------------|

Ordering and shipping details

| | |
|-------------------|--------------|
| Category | US10CP121193 |
| Discount Schedule | 0CP1 |
| Gtin | 785901788430 |
| Returnability | Yes |
| Country Of Origin | MX |

Packing Units

| | |
|------------------------------|-------------------------|
| Unit Type Of Package 1 | PCE |
| Number Of Units In Package 1 | 1 |
| Package 1 Height | 7.30 in (18.542 cm) |
| Package 1 Width | 8.70 in (22.098 cm) |
| Package 1 Length | 14.30 in (36.322 cm) |
| Package 1 Weight | 15.73 lb(US) (7.135 kg) |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

Sustainability

Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)

| | |
|---------------------------|---|
| Reach Regulation | REACH Declaration |
| Eu Rohs Directive | Not compliant |
| China Rohs Regulation | China RoHS declaration Product out of China RoHS scope. Substance declaration for your information. |
| California Proposition 65 | WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov |