


Product data sheet

Specifications

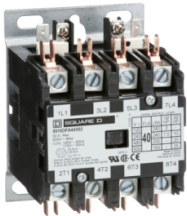

Contactor, Definite Purpose, 40A, 4 pole, 25HP at 575VAC, 3 phase, 110/120VAC 50/60Hz coil, open

8910DPA44V02

Product availability: Stock - Normally stocked in distribution facility

Price*: 146.75 USD

Main

Product Or Component Type	Definite Purpose Contactor
Line Rated Current	40 A
Number Of Poles	4P
Pole Contact Composition	4 NO
Range Of Product	DPA

Complementary

Maximum Horse Power Rating	3 hp 115 V AC, 1 phase 7.5 hp 230 V AC, 1 phase 10 hp 230 V AC, 3 phase 20 hp 460 V AC, 3 phase 25 hp 575 V AC, 3 phase
Locked Rotor Rated Current	240 A 277 V AC 200 A 460 V AC 160 A 575 V AC
[Ue] Rated Operational Voltage	600 V AC
[Uc] Control Circuit Voltage	120 V AC 60 Hz 110 V AC 50 Hz
Phase	3 phase
Electrical Connection	Box lugs Quick connect terminals

Environment

Product Certifications	UL Recognized CSA
------------------------	----------------------

Ordering and shipping details

Category	US1CP1B21344
Discount Schedule	CP1B
Gtin	785901073420
Returnability	Yes
Country Of Origin	MX

Packing Units

Unit Type Of Package 1	PCE
------------------------	-----

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Number Of Units In Package 1	1
Package 1 Height	3.20 in (8.128 cm)
Package 1 Width	2.90 in (7.366 cm)
Package 1 Length	4.00 in (10.16 cm)
Package 1 Weight	20.48 oz (580.598 g)

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability

Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)

Well-being performance



Mercury Free



Rohs Exemption Information

Yes

Reach Regulation

[REACH Declaration](#)

Eu Rohs Directive

Compliant with Exemptions

China Rohs Regulation

[China RoHS declaration](#)

Product out of China RoHS scope. Substance declaration for your information.