


Product data sheet

Specifications

SQUARE D

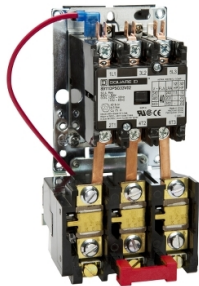

Definite Purpose Starter (Type: DPS) 30A, 3-Pole, 3-Phase, Open

8911DPSO33V07

Discontinued on: Jun 30, 2020

Discontinued

Main

Product	Definite Purpose Starter
Ampere Rating	30 A
Horsepower Rating	2 hp 115 V AC, 1 phase 5 hp 230 V AC, 1 phase 10 hp 230 V AC, 3 phase 15 hp 460 V AC, 3 phase 20 hp 575 V AC, 3 phase
Maximum Voltage Rating	600 V AC
Control Circuit Voltage	550 V AC 50 Hz 600 V AC 60 Hz
Phase	3 phase

Complementary

Enclosure Rating	Not rated (open device)
Locked Rotor Amperes	180 A 230 V AC 150 A 460 V AC 120 A 575 V AC
Number Of Poles	3P
Range	DPS
Overload Type	Melting alloy
Number Of Thermal Units	3

Ordering and shipping details

Category	21381-8911 DP
Discount Schedule	CP1
Gtin	00785901227953
Returnability	No
Country Of Origin	CN

Contractual warranty

Warranty	18 months
----------	-----------

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Sustainability



Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)

Well-being performance

	Mercury Free	
<hr/>		
	Rohs Exemption Information	Yes
<hr/>		
Eu Rohs Directive		Compliant
		EU RoHS Declaration
<hr/>		
China Rohs Regulation		China RoHS declaration
		Product out of China RoHS scope. Substance declaration for your information.
<hr/>		