


# Product data sheet

Specifications

SQUARE D

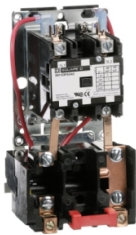

## Definite Purpose Starter (Type: DPS) 40A, 2-Pole, 1-Phase, Open

8911DPSO42V06

Discontinued on: Jul 12, 2021

Discontinued

### Main

Product	Definite Purpose Starter
Ampere Rating	40 A
Horsepower Rating	3 hp 115 V AC, 1 phase 7.5 hp 230 V AC, 1 phase
Maximum Voltage Rating	600 V AC
Control Circuit Voltage	440 V AC 50 Hz 480 V AC 60 Hz
Phase	1 phase

### Complementary

Enclosure Rating	Not rated (open device)
Locked Rotor Amperes	240 A 230 V AC 200 A 460 V AC 160 A 575 V AC
Number Of Poles	2P
Range	DPS
Overload Type	Melting alloy
Number Of Thermal Units	1

### Ordering and shipping details

Category	21381-8911 DP
Discount Schedule	CP1
Gtin	00785901227977
Returnability	No
Country Of Origin	CN

### Contractual warranty

Warranty	18 months
----------	-----------

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

# Sustainability



**Green Premium™ label** is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)

## Well-being performance

	Mercury Free	
<hr/>		
	Rohs Exemption Information	<a href="#">Yes</a>
<hr/>		
Eu Rohs Directive		Compliant
		<a href="#">EU RoHS Declaration</a>
<hr/>		
China Rohs Regulation		<a href="#">China RoHS declaration</a>
		Product out of China RoHS scope. Substance declaration for your information.
<hr/>		