


Product data sheet

Specifications

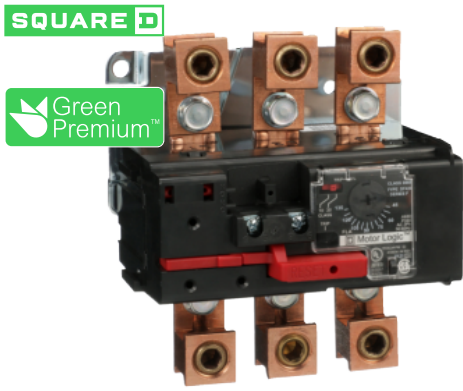

Overload Relay, Motor Logic, solid state overload relay, NEMA Size 4, 3 pole, 45A to 135A, 600VAC, separate mount

9065SF420

Product availability : Stock - Normally stocked in distribution facility

Price* : 545.00 USD

Main

Range of product	Motor Logic
Thermal overload type	Solid state

Complementary

NEMA size	4
Phase	3 phase
Mounting Support	Panel
[Ue] rated operational voltage	600 V AC
Height	5.92 in (150.4 mm)
Width	5.33 in (135.4 mm)
Depth	4.53 in (115.1 mm)

Ordering and shipping details

Category	21662 - 9065 SOLID STATE OVERLOAD RELAYS
Discount Schedule	CP1
GTIN	785901751960
Nbr. of units in pkg.	1
Package weight(Lbs)	3.31 lb(US) (1.5 kg)
Returnability	Yes
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	5.71 in (14.5 cm)
Package 1 width	7.01 in (17.8 cm)
Package 1 Length	7.09 in (18 cm)

* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information.
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information
PVC free	Yes

Contractual warranty

Warranty	18 months
-----------------	-----------