


Product data sheet

Specifications

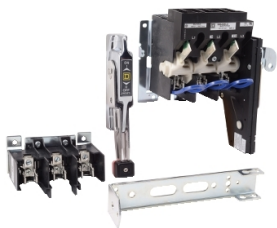

Operating mechanism, flange mounted, variable depth, 60A, 600V, fuseholder, switch mechanism, 6 inch handle, NEMA 4X

9422ATDF632

Product availability: Non-Stock - Not normally stocked in distribution facility

Price*: 869.20 USD

Main

| | |
|-----------------|---------------------------|
| Range | 9422T |
| Product | Disconnect Switch |
| Disconnect Type | Fusible disconnect switch |

Complementary

| | |
|-------------------|--|
| Mounting Type | Flange rod variable depth |
| Current Rating | 60 A |
| Horsepower Rating | 15 hp 200 V AC 15 hp 230 V AC 30 hp 460 V AC 50 hp 575 V AC 10 hp 250 V DC |
| Fuse Rating | 60 A 600 V |
| Handle Type | 6 in handle included NEMA 4/4X enclosures Stainless Steel |
| Fuse Type | J K R H |

Environment

| | |
|----------------|----------------------|
| Certifications | UL Recognized CSA |
|----------------|----------------------|

Ordering and shipping details

| | |
|-------------------|--------------|
| Category | US10CP121732 |
| Discount Schedule | 0CP1 |
| Gtin | 785901353201 |
| Returnability | No |
| Country Of Origin | MX |

Packing Units

| | |
|------------------------------|-----|
| Unit Type Of Package 1 | PCE |
| Number Of Units In Package 1 | 1 |

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

| | |
|------------------|-------------------------|
| Package 1 Height | 2.00 in (5.08 cm) |
| Package 1 Width | 4.00 in (10.16 cm) |
| Package 1 Length | 9.00 in (22.86 cm) |
| Package 1 Weight | 14.72 lb(US) (6.679 kg) |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

Sustainability




Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)

Well-being performance

| | |
|--|---|
|  Mercury Free | |
|  Rohs Exemption Information | Yes |
|  Pvc Free | |
| Reach Regulation | REACH Declaration |
| Eu Rohs Directive | Compliant with Exemptions |
| China Rohs Regulation | China RoHS declaration Product out of China RoHS scope. Substance declaration for your information. |
| California Proposition 65 | WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov |