


Product data sheet

Specifications

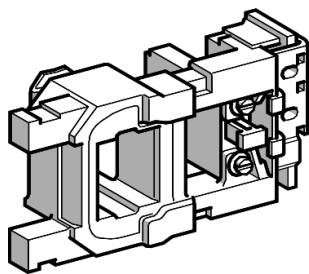

contactor coil - FF - 22 V DC

LX4FF022

⚠ Discontinued on: Jul 12, 2021

⚠ Discontinued

Main

Range	TeSys
Product Or Component Type	Contactor coil
Device Short Name	LX4FF
Range Compatibility	TeSys TeSys F LC1F contactor
Product Compatibility	LC1F150 LC1F115
Control Circuit Type	DC wide range
[Uc] Control Circuit Voltage	22 V DC
Average Resistance	0.88 Ohm inrush 68 °F (20 °C) 159 Ohm holding 68 °F (20 °C)
Operating Time	30...40 ms closing 30...50 ms opening
Maximum Operating Rate	60 cyc/h 131 °F (55 °C)

Complementary

Coil Technology	Without built-in suppressor module
Control Circuit Voltage Limits	Operational 0.85...1.1 Uc 131 °F (55 °C)) Drop-out 0.15...0.2 Uc 131 °F (55 °C))

Environment

Ambient Air Temperature For Operation	23...131 °F (-5...55 °C)
---------------------------------------	--------------------------

Ordering and shipping details

Category	18401-WORLD SERVICE PARTS(CTR ACCESS)
Discount Schedule	CP10
Gtin	3389118114630
Returnability	No

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	2.44 in (6.2 cm)
Package 1 Width	3.11 in (7.9 cm)

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Length	6.54 in (16.6 cm)
Package 1 Weight	15.17 oz (430 g)

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)

Well-being performance

✓	Reach Free Of Svhc	
✓	Toxic Heavy Metal Free	
✓	Mercury Free	
✓	Rohs Exemption Information	Yes
Eu Rohs Directive		
		Pro-active compliance (Product out of EU RoHS legal scope)
		EU RoHS Declaration
China Rohs Regulation		
		China RoHS declaration