


# Product data sheet

Specifications

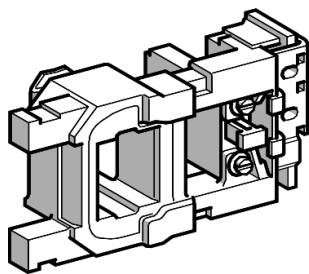

## contactor coil - FF - 30 V DC

LX4FF030

! Discontinued

### Main

Range	TeSys
Product Or Component Type	Contactor coil
Device Short Name	LX4FF
Range Compatibility	TeSys TeSys F LC1F contactor
Product Compatibility	LC1F150 LC1F115
Control Circuit Type	DC low consumption
[Uc] Control Circuit Voltage	30 V DC
Average Resistance	1.78 Ohm inrush 68 °F (20 °C) 296.7 Ohm holding 68 °F (20 °C)
Operating Time	30...40 ms closing 30...50 ms opening

### Complementary

Coil Technology	Without built-in suppressor module
Control Circuit Voltage Limits	Operational 0.85...1.1 Uc 131 °F (55 °C)) Drop-out 0.15...0.2 Uc 131 °F (55 °C))

### Environment

Ambient Air Temperature For Operation	23...131 °F (-5...55 °C)
---------------------------------------	--------------------------

### Ordering and shipping details

Category	18401-WORLD SERVICE PARTS(CTR ACCESS)
Discount Schedule	CP10
Gtin	3389110190496
Returnability	No

### Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1

### Contractual warranty

Warranty	18 months
----------	-----------

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

