


# Product data sheet

Specifications

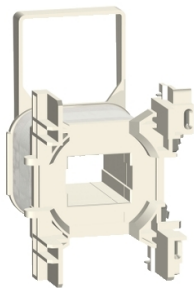

## Contactor coil, TeSys Deca, LXD3, 24V AC 50/60Hz for 40...65A contactor

LXD3B7

Product availability: Stock - Normally stocked in distribution facility

Price\*: 52.32 USD

### Main

Range	TeSys
Product Or Component Type	Contactor coil
Device Short Name	LXD3
Control Circuit Type	AC 50/60 Hz
[Uc] Control Circuit Voltage	24 V AC 50/60 Hz
Average Resistance	1.98 Ohm 68 °F (20 °C)
Inductance Of Closed Circuit	0.12 H
Product Compatibility	LC1DT60A LC1D40A...D65A LC1DT80A
Mechanical Durability	6 Mcycles
Maximum Operating Rate	3600 cyc/h 140 °F (60 °C)

### Complementary

Coil Technology	Without built-in suppressor module
Control Circuit Voltage Limits	Drop-out: 0.3...0.6 Uc at 50/60 Hz (at <140 °F (60 °C)) Operational: 0.8...1.1 Uc at 50 Hz (at <140 °F (60 °C)) Operational: 0.85...1.1 Uc at 60 Hz (at <140 °F (60 °C))
Inrush Power In Va	160 VA 60 Hz cos phi 0.75 (at 68 °F (20 °C)) 160 VA 50 Hz cos phi 0.75 (at 68 °F (20 °C))
Hold-In Power Consumption In Va	15 VA 60 Hz cos phi 0.3 (at 68 °F (20 °C)) 15 VA 50 Hz cos phi 0.3 (at 68 °F (20 °C))
Heat Dissipation	4...5 W 50/60 Hz

### Environment

Ambient Air Temperature For Operation	23...140 °F (-5...60 °C)
Net Weight	0.15 lb(US) (0.07 kg)

### Ordering and shipping details

Category	US10I1222341
Discount Schedule	0I12
Gtin	3389119410304
Returnability	Yes

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Country Of Origin	US
-------------------	----

## Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	2.24 in (5.7 cm)
Package 1 Width	2.28 in (5.8 cm)
Package 1 Length	3.86 in (9.8 cm)
Package 1 Weight	4.27 oz (121.0 g)
Unit Type Of Package 2	S02
Number Of Units In Package 2	30
Package 2 Height	5.91 in (15 cm)
Package 2 Width	11.81 in (30 cm)
Package 2 Length	15.75 in (40 cm)
Package 2 Weight	8.79 lb(US) (3.988 kg)

## Contractual warranty

Warranty	18 months
----------	-----------

## Sustainability

**Green Premium™ label** is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)

## Well-being performance

✓	Reach Free Of Svhc	
✓	Toxic Heavy Metal Free	
✓	Mercury Free	
✓	Rohs Exemption Information	Yes
✓	Pvc Free	
Reach Regulation	<a href="#">REACH Declaration</a>	
Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>	
China Rohs Regulation	<a href="#">China RoHS declaration</a> Pro-active China RoHS declaration (out of China RoHS legal scope)	
California Proposition 65	WARNING: This product can expose you to chemicals including: Antimony oxide & Antimony trioxide, which is known to the State of California to cause cancer. For more information go to <a href="#">www.P65Warnings.ca.gov</a>	