


# Product data sheet

Specifications

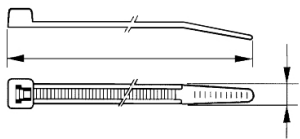

Adjustable cable tie 295x3.6 black .  
Polyamide 6/6. Composition: 1000  
units.

NSYLN35290

! Discontinued

## Main

Accessory / Separate Part Category	Cable management accessory
Product Or Component Type	Cable tie
Application	Multi-purpose
Device Composition	1 cable tie
Quantity Per Set	Set of 1000

## Complementary

Mounting Support	Cable ties fixing supports
Material	Black polyamide 6/6
Length	11.61 in (295 mm)
Width	0.14 in (3.6 mm)

## Environment

Fire Resistance	1202 °F (650 °C) UL 94 V2
Environmental Characteristic	Not sensitive to engine oil, greases, oil products, etc Good resistance to bases and organic acids, chlorinated solvent Not resistant to phenol
Maximum Tightening Diameter	2.99 in (76 mm)
Minimum Pulling Resistance	13.6 Ohm

## Ordering and shipping details

Category	80036-ENCLOSURE SYSTEMS ACCESSORIES
Discount Schedule	ES1
Gtin	3606480182174
Returnability	No
Country Of Origin	TW

## Contractual warranty

Warranty	18 months
----------	-----------

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications