


Product data sheet

Specifications

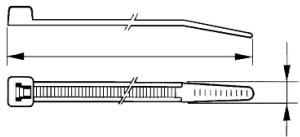

Adjustable cable tie 390x4.6 black .
Polyamide 6/6. Composition: 1000
units.

NSYLN48390

⚠ Discontinued on: Dec 2, 2020

⚠ End-of-service on: Dec 31, 2020

⚠ Discontinued

Main

Accessory / Separate Part Category	Cable management accessory
Product Or Component Type	Cable tie
Application	Multi-purpose
Device Composition	1 cable tie
Quantity Per Set	Set of 1000

Complementary

Mounting Support	Cable ties fixing supports
Material	Black polyamide 6/6
Length	15.35 in (390 mm)
Width	0.19 in (4.8 mm)

Environment

Fire Resistance	1202 °F (650 °C) UL 94 V2
Environmental Characteristic	Not sensitive to engine oil, greases, oil products, etc Good resistance to bases and organic acids, chlorinated solvent Not resistant to phenol
Maximum Tightening Diameter	4.29 in (109 mm)
Minimum Pulling Resistance	22 Ohm

Ordering and shipping details

Gtin	3606480182259
------	---------------

Contractual warranty

Warranty	18 months
----------	-----------

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.