


# Product data sheet

Specifications

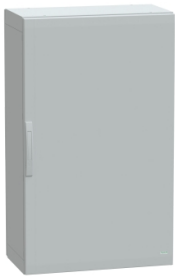

Floor standing polyester enclosure, Thalassa PLA, plain door, completely sealed, 1250x750x420mm, IP65, IK10

NSYPLA1274G

Product availability: Non-Stock - Not normally stocked in distribution facility

Price\*: 891.25 USD

## Main

Range	Thalassa
Product Name	Thalassa PLA
Enclosure Type	Multi-purpose
Product Or Component Type	Suitable enclosure
Version	PLA
Nominal Height	49.21 in (1250 mm)
Nominal Width	29.53 in (750 mm)
Nominal Depth	16.54 in (420 mm)
Enclosure Mounting	Floor-standing
Device Composition	1 top part 1 bottom part 2 side part 1 rear panel 1 door

## Complementary

Body Type	Sealed top and bottom part assembled with side parts
Door Type	Solid front
Number Of Doors	1
Door Opening Side	Reversible 120 °)
Lock Type	4 points lock, 5 mm double-bar
Accessibility For Operation	Rear Front
Removable Parts	Door by hinges Rear panel by fixing element
Material	polyester reinforced with fibreglass
Color	Gray RAL 7035)
Standards	UL 508 A IEC 62208

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Nema Degree Of Protection	NEMA 3R NEMA 3 NEMA 3S NEMA 1 NEMA 13 NEMA 2 NEMA 12 NEMA 5 NEMA 3X
Product Certifications	DNV Marine Veritas UL/cUL listed
Electrical Insulation Class	Class II

## Environment

Ip Degree Of Protection	IP65 IEC 60529 completely sealed)
Ik Degree Of Protection	IK10 IEC 62262 plain door)
Fire Resistance	1760 °F (960 °C) IEC 62208
Ambient Air Temperature For Storage	-31...194 °F (-35...90 °C)

## Ordering and shipping details

Category	US10ES180034
Discount Schedule	0ES1
Gtin	3606480774652
Returnability	No
Country Of Origin	ES

## Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	49.61 in (126.0 cm)
Package 1 Width	30.71 in (78.0 cm)
Package 1 Length	18.90 in (48.0 cm)
Package 1 Weight	83.78 lb(US) (38.0 kg)
Unit Type Of Package 2	PAM
Number Of Units In Package 2	2
Package 2 Height	47.24 in (120 cm)
Package 2 Width	39.37 in (100 cm)
Package 2 Length	55.12 in (140 cm)
Package 2 Weight	180.78 lb(US) (82 kg)

Sustainability



**Green Premium™ label** is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



Transparency   RoHS/REACH

## Well-being performance

 Mercury Free

 RoHS Exemption Information   [Yes](#)

## Certifications & Standards

Reach Regulation	<a href="#">REACH Declaration</a>
Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope)
China Rohs Regulation	<a href="#">China RoHS declaration</a> Product out of China RoHS scope. Substance declaration for your information.
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	No need of specific recycling operations