


# Product data sheet

Specifications

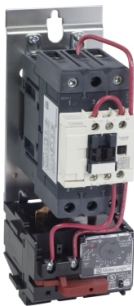

Motor Starter, TeSys NEMA, nonreversing, Size 2, 45A, 3 pole, HP rated, Motor Logic SSOLR, 120 VAC 60 Hz coil, open

T36DN13G7

Product availability: Non-Stock - Not normally stocked in distribution facility

Price\*: 754.00 USD

## Main

Product	Starter
Range Of Product	TeSys N
Current Rating	45 A
Certifications	UL Listed CSA
Control Circuit Type	Common control circuit
Enclosure Type	Not rated (open device)
Auxiliary Contacts	1 NO + 1 NC
Horsepower Rating	10 HP 200 V AC 15 HP 230 V AC 25 HP 460 V AC 25 HP 575 V AC
Number Of Poles	3P
Phase	3 phase
Maximum Voltage Rating	600 V AC
Nema Size	2
Control Circuit Voltage	120 V AC
Starter Type	Non reversing
Electrical Connection	Screw clamp terminals
Overload Type	Solid state Motor Logic class 10/20 15...45 A

## Ordering and shipping details

Category	US10CP121198
Discount Schedule	0CP1
Gtin	785901958123
Returnability	Yes
Country Of Origin	US

## Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Weight

8.10 lb(US) (3.674 kg)

# Sustainability




**Green Premium™ label** is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)

## Well-being performance

 Reach Free Of Svhc	
 Mercury Free	
 Rohs Exemption Information	Yes
Reach Regulation	<a href="#">REACH Declaration</a>
Eu Rohs Directive	Compliant with Exemptions
China Rohs Regulation	<a href="#">China RoHS declaration</a> Product out of China RoHS scope. Substance declaration for your information.
California Proposition 65	WARNING: Cancer and Reproductive Harm - <a href="#">www.P65Warnings.ca.gov</a>