

# Product data sheet

Specifications



braking resistor - 27 ohm - 400 W -  
cable 2 m - IP65

VW3A7604R20

Product availability: Non-Stock - Not normally stocked in  
distribution facility

Price\*: 306.00 USD

## Main

Range Of Product	Lexium Altivar
Range Compatibility	Lexium 15 Lexium 52 Lexium 32i Lexium 32 Lexium 05 Lexium 28 Easy Lexium 16
Product Compatibility	Motion servo drive LXM16D 0.75 kW, 200...230 V, single phase Motion servo drive LXM16D 1 kW, 200...230 V, single phase Motion servo drive LXM16D 1.5 kW, 200...230 V, single phase
Product Or Component Type	Braking resistor
Ohmic Value	27 Ohm

## Complementary

Energy Peak	10500 J 480 V 11400 J 400 V 18100 J 230 V 25500 J 115 V
Continuous Power	400 W
Protection Type	Thermal protection via the servo drive
Net Weight	3.24 lb(US) (1.47 kg)
Cable Length	6.56 ft (2 m)

## Environment

Ip Degree Of Protection	IP65
Ambient Air Temperature For Storage	-13...185 °F (-25...85 °C)
Ambient Air Temperature For Operation	32...122 °F (0...50 °C)

## Ordering and shipping details

Category	US1PC5118263
Discount Schedule	PC51
Gtin	3389119207188
Returnability	No
Country Of Origin	DE

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

## Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	1.77 in (4.500 cm)
Package 1 Width	4.92 in (12.500 cm)
Package 1 Length	15.55 in (39.500 cm)
Package 1 Weight	3.56 lb(US) (1.614 kg)
Unit Type Of Package 2	CAR
Number Of Units In Package 2	6
Package 2 Height	10.24 in (26.000 cm)
Package 2 Width	8.66 in (22.000 cm)
Package 2 Length	16.54 in (42.000 cm)
Package 2 Weight	21.98 lb(US) (9.968 kg)
Unit Type Of Package 3	P12
Number Of Units In Package 3	108
Package 3 Height	37.40 in (95.000 cm)
Package 3 Width	31.50 in (80.000 cm)
Package 3 Length	47.24 in (120.000 cm)
Package 3 Weight	439.65 lb(US) (199.420 kg)

## Contractual warranty

Warranty	18 months
----------	-----------

## Sustainability

**Green Premium™ label** is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)

## Well-being performance


✓	Reach Free Of Svhc	
✓	Mercury Free	
✓	Rohs Exemption Information	Yes
✓	Pvc Free	
Reach Regulation		<a href="#">REACH Declaration</a>
Eu Rohs Directive		Pro-active compliance (Product out of EU RoHS legal scope)
China Rohs Regulation		<a href="#">China RoHS declaration</a>
California Proposition 65		WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>

Dimensions Drawings

Braking Resistor

---

Dimensions

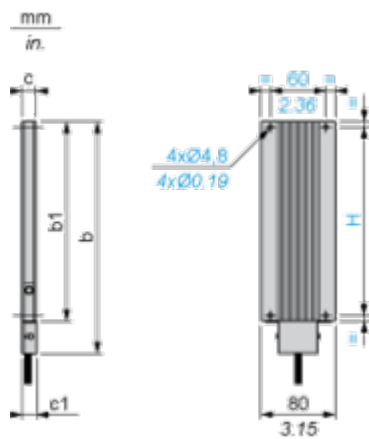

Dimensions in mm

b	b1	c	c1	H
257	216	30	–	204

Dimensions in in.

b	b1	c	c1	H
10.11	8.50	1.18	–	8.03