


Product data sheet

Specifications



empty pendant control station XAC-F - without opening

XACF0050

 **Discontinued on:** Oct 20, 2020

 **Discontinued**

Main

Range Of Product	Harmony XAC
Product Or Component Type	Pendant control station
Device Short Name	XACF

Complementary

Control Station Type	Double insulated
Enclosure Material	Glass reinforced polyester
Electrical Circuit Type	Control circuit
Enclosure Type	Empty enclosure
Number Of Cut-Out	Without cut-out
Control Station Colour	Yellow
Cable Entry	Rubber sleeve with stepped entry 0.87...1.38 in (22...35 mm)
Guard Rail	Without
Standards	EN/IEC 60947-5-1 CSA C22.2 No 14 UL 508
Protective Treatment	TH
Ambient Air Temperature For Operation	-13...158 °F (-25...70 °C)
Ambient Air Temperature For Storage	-40...158 °F (-40...70 °C)
Vibration Resistance	15 gn 10...500 Hz)IEC 60068-2-6
Shock Resistance	100 gn IEC 60068-2-27
Overvoltage Category	Class II IEC 61140
Ip Degree Of Protection	IP65 conforming to IEC 60529
Ik Degree Of Protection	IK08 conforming to EN 50102
Mechanical Durability	1000000 cycles
Net Weight	5.07 lb(US) (2.3 kg)

Ordering and shipping details

Category	22473-PUSHBUTTON, PENDANTS
Discount Schedule	CS2
Gtin	3389110891515

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Returnability	No
Country Of Origin	FR

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	5.91 in (15 cm)
Package 1 Width	6.30 in (16 cm)
Package 1 Length	24.80 in (63 cm)
Package 1 Weight	5.96 lb(US) (2.704 kg)

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability





Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.


[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)

Well-being performance


	Reach Free Of Svhc	
	Toxic Heavy Metal Free	
	Mercury Free	
	Rohs Exemption Information	Yes
Reach Regulation		REACH Declaration
Eu Rohs Directive		Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
China Rohs Regulation		China RoHS declaration
Weee		The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.
California Proposition 65		WARNING: This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

Dimensions

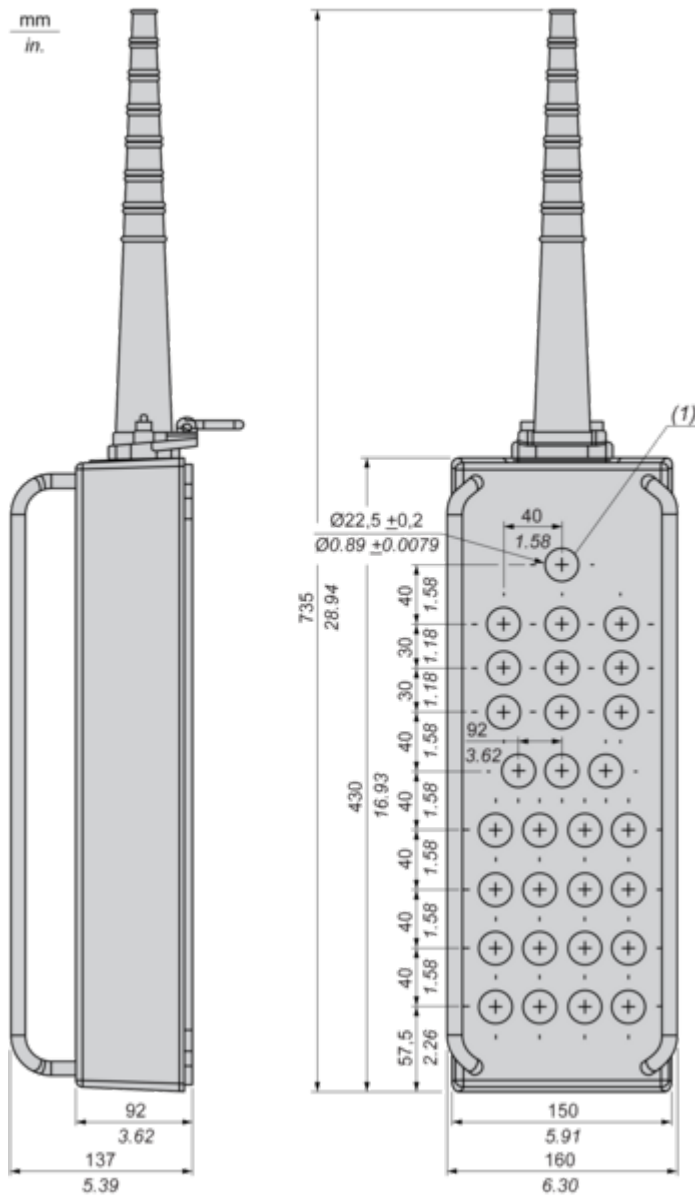


(1) Position Emergency STOP

Protective Cable Sleeves

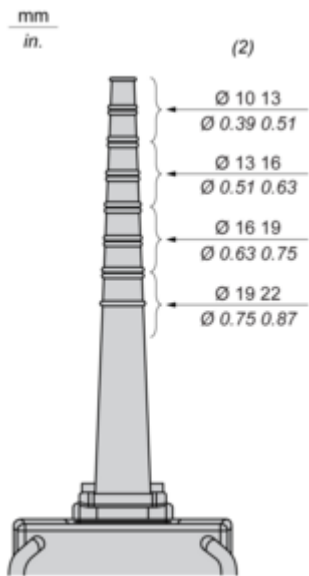

(2) Internal ø (mm/in.)


Protective Cable Sleeves

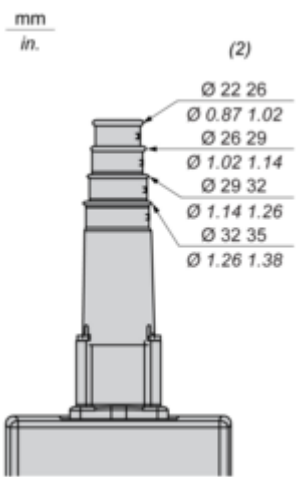

(2) Internal ø (mm/in.)

Mounting and Clearance

Mounting of Pendant Box

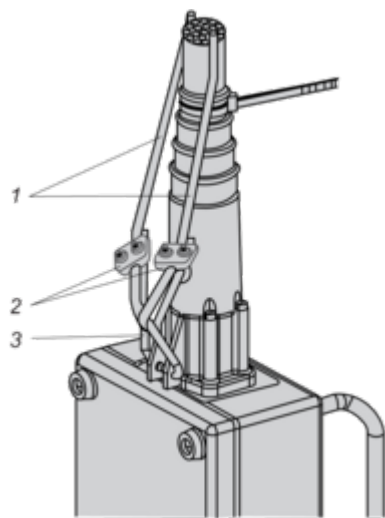


- 1 : Sustentation cables
- 2 : Cables clamp
- 3 : Ring

Connections and Schema


Control of Single-Speed Reversing Motor

With XESD1181 contact block, to be ordered separately

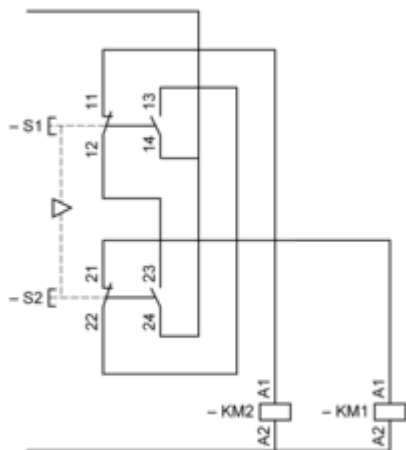

Control of 2-Speed Reversing Motor

With XESD1281 contact block, to be ordered separately

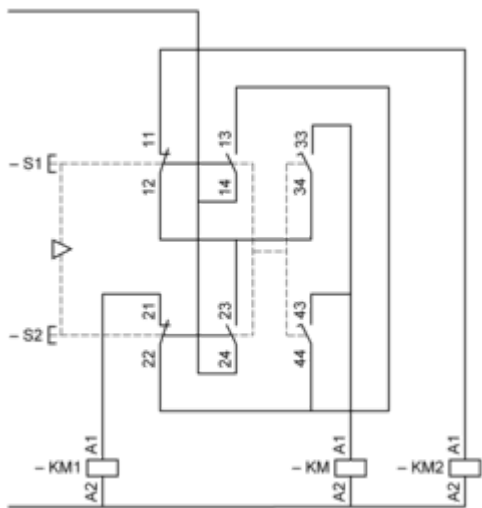

KM High speed contactor