


Product data sheet

Specifications

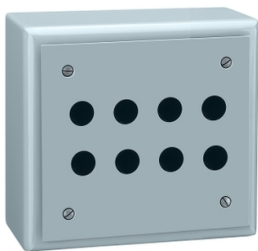

Empty control station, Harmony XAP, XB2 SL, metal, blue, 8 cut outs, 22mm, 200x200x120mm

XB2SL42007

⚠ Discontinued on: Mar 31, 2022

⚠ Discontinued

Main

Range Of Product	Harmony XAP
Product Or Component Type	Empty control station
Device Short Name	XB2SL
Product Destination	For Ø 22 mm control and signalling units
Product Front Plate Size	200 x 200 mm
Usable Depth	4.53 in (115 mm)
Number Of Cut-Out	8 cut-outs
Material	Sheet steel
Product Mounting	Flush mounting
Ip Degree Of Protection	IP54 IEC 60529 IP547 NF C 20-010

Complementary

Number Of Vertical Rows	4
Net Weight	6.83 lb(US) (3.1 kg)

Environment

Protective Treatment	TC
Ambient Air Temperature For Storage	-40...158 °F (-40...70 °C)
Ambient Air Temperature For Operation	-13...158 °F (-25...70 °C)
Electrical Shock Protection Class	Class I IEC 60536 Class I NF C 20-030

Ordering and shipping details

Category	18406-WORLD SERVICE PARTS(OTHER OP INT)
Discount Schedule	CS2
Gtin	3389110636963
Returnability	No
Country Of Origin	FR

Packing Units

Unit Type Of Package 1	PCE
------------------------	-----

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Number Of Units In Package 1	1
Package 1 Height	7.09 in (18.000 cm)
Package 1 Width	8.66 in (22.000 cm)
Package 1 Length	10.43 in (26.500 cm)
Package 1 Weight	7.76 lb(US) (3.519 kg)
Unit Type Of Package 2	P06
Number Of Units In Package 2	6
Package 2 Height	29.53 in (75.000 cm)
Package 2 Width	23.62 in (60.000 cm)
Package 2 Length	31.50 in (80.000 cm)
Package 2 Weight	75.21 lb(US) (34.114 kg)

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability





Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)


[Guide to assess a product's sustainability >](#)

Well-being performance

	Reach Free Of Svhc	
	Toxic Heavy Metal Free	
	Mercury Free	
	Rohs Exemption Information	Yes
Reach Regulation		REACH Declaration
Eu Rohs Directive		Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
China Rohs Regulation		China RoHS declaration
Weee		The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.
Circularity Profile		No need of specific recycling operations
California Proposition 65		WARNING: This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

Dimensions Drawings

Dimensions

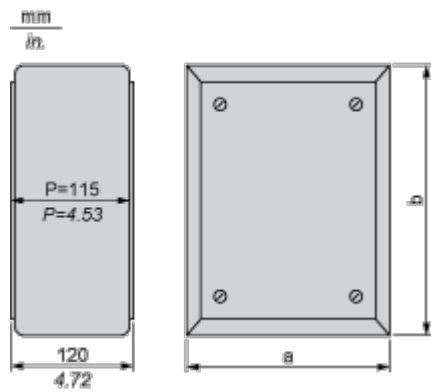


P Usable depth

a		b	
mm	in.	mm	in.
200	7.87	200	7.87

Refer to the product characteristics to get the number of cut-outs.

Cut-out interaxis dimensions (vertical mounting)

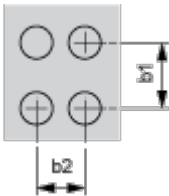

- b1 Vertical interaxis: 40 mm/1.57 in.
- b2 Horizontal interaxis: 30 mm/1.18 in.