


Product datasheet

Specifications

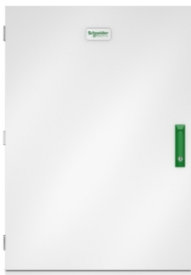

Parallel Maintenance Bypass Panel, 10-200kVA 400V wallmount, for Easy UPS 3S/3M

E3MBPAR60K200H

Overview

Presentation	Maintenance bypass panel for complete isolation of an Easy UPS 3M in parallel during service operations. Up to three UPSs can be isolated.
Lead Time	Usually Ships within 6 Weeks

Physical

Colour	White
Height	100 cm
Width	70 cm
Depth	32 cm
Net Weight	62 kg
Mounting Location	Front
Mounting Preference	No preference
Mounting Mode	Not rack-mountable

Environmental

Ambient Air Temperature For Operation	0...40 °C
Ambient Air Temperature For Storage	-25...55 °C
Storage Relative Humidity	0...95 % non-condensing

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	120 cm
Package 1 Width	57 cm
Package 1 Length	80 cm
Package 1 Weight	92 kg

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Sustainability




Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)

Well-being performance

	Toxic Heavy Metal Free	
	Mercury Free	
	Rohs Exemption Information	Yes
Reach Regulation		REACH Declaration
Eu Rohs Directive		Compliant with Exemptions
China Rohs Regulation		China RoHS declaration
		Product out of China RoHS scope. Substance declaration for your information