


Product datasheet

Specifications

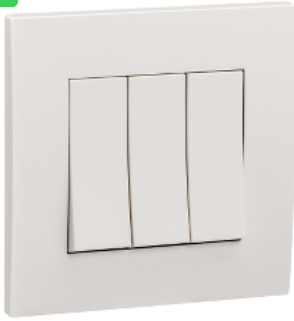

Vivace - switch h - 2way - 16AX 250V -3 gangs - White

KB33_WE

! Discontinued on: 23 January 2021

! End-of-service on: 24 January 2021

! Discontinued - Service only

Main

| | |
|-------------------------------|--------------------|
| Range | Vivace |
| Product or component type | Switch |
| Device short name | KB33 |
| Device application | Control |
| Device presentation | Complete mechanism |
| Additional switch application | Switch |

Complementary

| | |
|--------------------------------|---|
| Switch function | 2-way |
| Actuator | Rocker |
| Number of gangs | 3 gangs |
| Colour tint | White |
| Material | Polycarbonate: grid plate Polycarbonate: surround Polycarbonate: base |
| Surface finish | Glossy |
| Type of packing | Plastic bag |
| Quantity per set | 1 |
| Projecting depth | 8 mm |
| Device mounting | Flush |
| Mounting support | Wall mounted |
| Fixing mode | By screw M3.5 |
| Fixing center | 60.3 mm |
| Embedding depth | 35 mm |
| Rated current | 16 AX at 250 V AC, inductive 16 AX at 250 V AC, fluorescent |
| [Ue] rated operational voltage | 250 V AC |
| Network frequency | 50 Hz |
| Contacts material | Brass and phosphor bronze |
| Connections - terminals | pillar terminal |

| | |
|------------------------------|---------------------|
| Terminal identifier | COM L1 L2 |
| Tightening torque | 0.4 N.m |
| Clamping connection capacity | 2.5 mm ² |
| Wire stripping length | 12 mm |
| Width | 87 mm |
| Height | 87 mm |

Environment

| | |
|---------------------------------------|---|
| Standards | IEC 60669-1 SS 227 MS IEC 60669-1 |
| Ambient air temperature for operation | -5...40 °C |
| Relative humidity | 0...95 % |
| Environmental characteristic | Indoor use |

Packing Units

| | |
|------------------------------|--------|
| Unit Type of Package 1 | PCE |
| Number of Units in Package 1 | 1 |
| Package 1 Height | 4 cm |
| Package 1 Width | 8.5 cm |
| Package 1 Length | 8.5 cm |
| Package 1 Weight | 84 g |
| Unit Type of Package 2 | BB1 |
| Number of Units in Package 2 | 8 |
| Package 2 Height | 9.5 cm |
| Package 2 Width | 15 cm |
| Package 2 Length | 19 cm |
| Package 2 Weight | 760 g |
| Unit Type of Package 3 | CAR |
| Number of Units in Package 3 | 80 |
| Package 3 Height | 21 cm |
| Package 3 Width | 32 cm |
| Package 3 Length | 50 cm |
| Package 3 Weight | 8266 g |

Offer Sustainability

| | |
|----------------------------|---|
| Sustainable offer status | Green Premium product |
| REACH Regulation | REACH Declaration |
| EU RoHS Directive | Compliant EU RoHS Declaration |
| Mercury free | Yes |
| RoHS exemption information | Yes |
| China RoHS Regulation | China RoHS declaration Product out of China RoHS scope. Substance declaration for your information |

Recommended replacement(s)