

Product datasheet

Specifications



Complete pre wired monolithic tower light, Harmony XVC, plastic, red orange, 100mm, base mounting, steady or flashing, siren, IP54, 24V DC

XVC1B2HK

Main

Range Of Product	Harmony XVC1
Product Or Component Type	Complete pre-wired monolithic tower light
Beacon Or Indicator Bank Unit Type	2 illuminated units
Sound Signalling	Siren
Mounting Diameter	100 mm
Component Name	XVC
Light Source	LED steady or flashing red LED steady or flashing orange
[Us] Rated Supply Voltage	24 V
Supply Circuit Type	DC
Noise Level	0...102 dB (continuous or intermittent tone) at 1 m

Complementary

Material	Polycarbonate: illuminated unit ABS (acrylonitrile butadiene-styrene): base unit PBT + ABS (UL94-V0): top cover
Product Mounting	On base
Cable Cross Section	0.33 mm² 0.83 mm²
Awg Gauge	AWG 18 AWG 22
Cable Length	500 mm
Marking	CE
[Uimp] Rated Impulse Withstand Voltage	0.8 kV
Current Consumption	550 mA
Flashing Frequency	0.7...3 Hz
Net Weight	1.78 kg
Height	371 mm

Environment

Standards	IEC 61000-6-2 IEC 61000-6-3 IEC 61000-6-4
Product Certifications	UL

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Protective Treatment	TC
Ambient Air Temperature For Storage	-35...70 °C
Ambient Air Temperature For Operation	-20...50 °C
Electrical Shock Protection Class	Class II conforming to IEC 61140
Ip Degree Of Protection	IP54 conforming to IEC 60529

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	18 cm
Package 1 Width	18 cm
Package 1 Length	63 cm
Package 1 Weight	2.66 kg

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency

Well-being performance

✓ Mercury Free

✓ Rohs Exemption Information [Yes](#)

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope)
-------------------	--

China Rohs Regulation	China RoHS declaration
-----------------------	--

Environmental Disclosure	Product Environmental Profile
--------------------------	---


Circularity Profile	End of Life Information
---------------------	---

Dimensions Drawings

Pre-assembled and Pre-wired Tower Light with Siren

Dimensions

Below drawing shows the maximum configuration of the product. Select the number of stages according to the product characteristics in order to get **b** dimension.

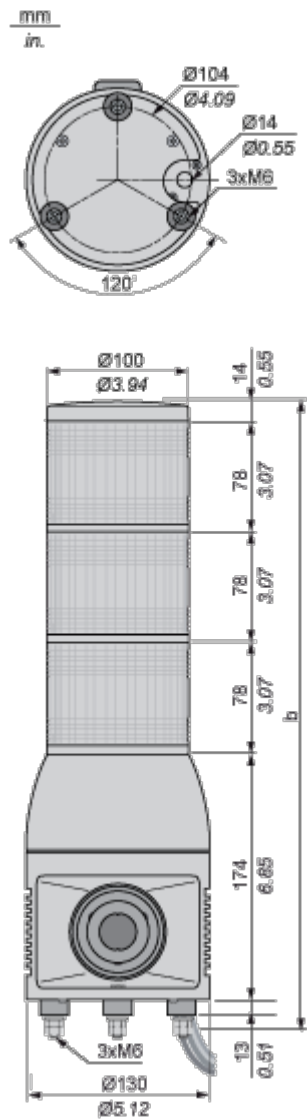

No. of illuminated units	b in mm	b in in.
1	293	11.54
2	371	14.61
3	449	17.68

Mounting and Clearance

Pre-assembled and Pre-wired Tower Light with Siren

Mounting on Horizontal Support (Direct or with Fixing Plate)

Panel cut-out

$$\frac{\text{mm}}{\text{in.}}$$
