

# Product datasheet

Specifications



Complete pre wired monolithic tower light, Harmony XVC, plastic, red, 40mm, tube mounting, steady or flashing, buzzer, IP23, 24V AC DC

XVC4B15S

## Main

Range Of Product	Harmony XVC4
Product Or Component Type	Complete pre-wired monolithic tower light
Beacon Or Indicator Bank Unit Type	1 illuminated unit
Sound Signalling	Buzzer
Mounting Diameter	40 mm
Component Name	XVC
Device Short Name	XVC
Light Source	LED steady or flashing red
Supply Circuit Type	AC/DC
Noise Level	70...85 dB (continuous or intermittent tone) at 1 m

## Complementary

Material	Polycarbonate: illuminated unit ABS (acrylonitrile butadiene-styrene): base unit PBT + ABS (UL94HB): top cover SGP (chromium-plated): support tube
Mounting Location	On support tube, 17 mm
Product Mounting	On support tube, 17 mm
[Us] Rated Supply Voltage	24 V
[Us] Rated Supply Voltage	24 V
Cable Cross Section	0.33 mm²
Awg Gauge	AWG 22
Cable Length	900 mm
Marking	CE
[Uimp] Rated Impulse Withstand Voltage	0.8 kV
Current Consumption	65 mA
Fundamental Frequency	2.23 kHz
Flashing Frequency	1 Hz
Net Weight	0.6 kg
Height	524.5 mm

## Environment

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Standards	IEC 61000-6-3 IEC 61000-6-2
Product Certifications	UL
Protective Treatment	TC
Ambient Air Temperature For Storage	-35...70 °C
Ambient Air Temperature For Operation	-10...50 °C
Electrical Shock Protection Class	Class I conforming to IEC 61140
Overvoltage Category	Class I conforming to IEC 61140
Ip Degree Of Protection	IP23 vertical surface installation conforming to IEC 60529

## Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	7.000 cm
Package 1 Width	75.000 cm
Package 1 Length	7.000 cm
Package 1 Weight	676.000 g
Unit Type Of Package 2	BB1
Number Of Units In Package 2	10
Package 2 Height	17.000 cm
Package 2 Width	36.000 cm
Package 2 Length	77.000 cm
Package 2 Weight	7.713 kg
Unit Type Of Package 3	P06
Number Of Units In Package 3	30
Package 3 Height	75.000 cm
Package 3 Width	80.000 cm
Package 3 Length	60.000 cm
Package 3 Weight	31.139 kg

## Contractual warranty

Warranty	18 months
----------	-----------

# Sustainability

**Green Premium™ label** is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency

## Well-being performance


✓	Mercury Free	
✓	Rohs Exemption Information	Yes
Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope)	
China Rohs Regulation	<a href="#">China RoHS declaration</a>	
Environmental Disclosure	<a href="#">Product Environmental Profile</a>	
Circularity Profile	<a href="#">End of Life Information</a>	

## Dimensions Drawings

### **Pre-assembled and Pre-wired Tower Light with Support Tube Mounting**

## Dimensions

Below drawing shows the maximum configuration of the product. Select the number of stages according to the product characteristics in order to get **b1** dimension.

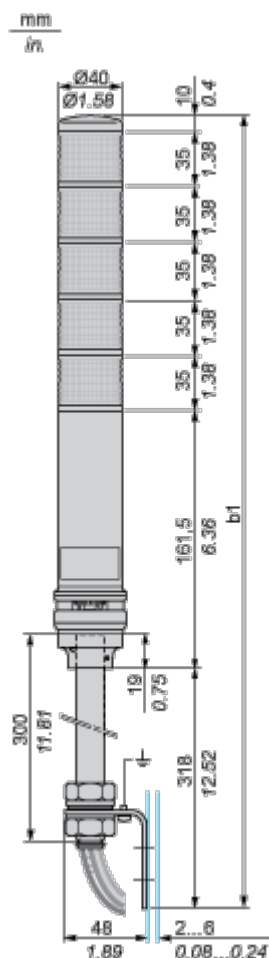

No. of illuminated units	b1 With buzzer (mm)	b1 With buzzer (in.)
1 stage	524.50	20.65
2 stages	559.50	22.03
3 stages	594.50	23.41
4 stages	629.50	24.78
5 stages	664.50	26.16

## Mounting and Clearance

### Pre-assembled and Pre-wired Tower Light

## Support Tube Mounting

