


Bảng thông số sản phẩm

Thông số kỹ thuật

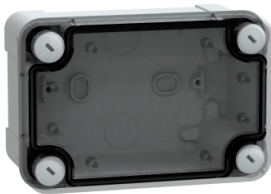

PC box IP66 IK08 RAL7035
Int.H125W80D65
Ext.H138W93D72 Transp.cover
H20

NSYTBP1397T

Main

Range	Thalassa
Product Name	Thalassa TBP
Device Application	Multi-purpose
Category	Industrial box
Height	138 mm
Width	93 mm
Depth	72 mm
Internal Height	125 mm
Internal Width	80 mm
Internal Depth	65 mm
Enclosure Mounting	Wall mounted
Device Composition	1 body 1 cover 4 cover screw
Quantity Per Set	Set of 2
Body Type	One piece moulded
Type Of Front Cover	Low transparent cover
Cover Fixing	Plastic screws
Lock Type	Captive screw flat outside sealed area
Removable Parts	Cover by captive screws

Complementary

Material	Polycarbonate
Colour	Grey (RAL 7035) Transparent
Standards	IEC 62208 UL 508 A
Product Certifications	TÜV UL
Electrical Insulation Class	Class II
Mounting Location	Outdoor (with canopy or shelter and anticondensation valve)
Net Weight	0.23 kg

Environment

Miễn trừ trách nhiệm: Tài liệu này không nhằm thay thế và không được sử dụng để xác định tính phù hợp hoặc độ tin cậy của các sản phẩm này cho các ứng dụng người dùng cụ thể

Ip Degree Of Protection	IP66 conforming to NEMA 4.4X
Ik Degree Of Protection	IK08 conforming to IEC 62262
Fire Resistance	960 °C
Ambient Air Temperature For Storage	-15...60 °C
Operating Temperature	-25...80 °C

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	7.2 cm
Package 1 Width	9.3 cm
Package 1 Length	13.8 cm
Package 1 Weight	230 g
Unit Type Of Package 2	PAM
Number Of Units In Package 2	1160
Package 2 Height	120 cm
Package 2 Width	100 cm
Package 2 Length	173 cm
Package 2 Weight	404 kg

Contractual warranty

Warranty	18 months
----------	-----------

Bền vững

Nhãn **Green Premium™** là cam kết của Schneider Electric trong việc cung cấp sản phẩm với hiệu suất môi trường tốt nhất. Green Premium cam kết tuân thủ các quy định mới nhất, minh bạch về tác động môi trường, cũng như các sản phẩm tuần hoàn và CO₂ thấp.

Hướng dẫn đánh giá tính bền vững của sản phẩm là tài liệu kỹ thuật phổ thông giúp làm rõ các tiêu chuẩn nhãn sinh thái toàn cầu và cách diễn giải việc khai báo môi trường.

[Tìm hiểu thêm về Green Premium >](#)

[Hướng dẫn đánh giá về sự bền vững của sản phẩm >](#)



Minh bạch RoHS/REACH

Hiệu suất sức khỏe

✓ Reach Free Of Svhc	
✓ Toxic Heavy Metal Free	
✓ Mercury Free	
✓ Rohs Exemption Information	Yes

Chứng nhận & Tiêu chuẩn

Reach Regulation	REACH Declaration
Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information