

Bảng thông số sản phẩm

Thông số kỹ thuật



solid state relay - DIN rail mount -
input 4-32 V DC, output 1-60 V DC
,6A

SSM1D26BD

⚠ Ngừng sản xuất vào: 1 thg 11, 2020

⚠ Ngừng sản xuất

Main

Range Of Product	Harmony Solid State Relays
Product Or Component Type	Solid state relay up to 10 A
Device Short Name	SSM
Number Of Channels	1
Number Of Phases	1 phase
Output Switching Mode	DC switching

Complementary

Mounting Support	Symmetrical DIN rail
[In] Rated Current	6 A
Output Voltage	1...60 V DC
[Uc] Control Circuit Voltage	4...32 V DC
Tightening Torque	0.5...0.8 N.m for input 0.5...0.8 N.m for output
Connections - Terminals	Screw terminals: 1 x 0.3...1 x 1.5 mm ² , (AWG 22...AWG 16) for input Screw terminals: 1 x 0.3...1 x 2.5 mm ² , (AWG 22...AWG 14) for output
Maximum Capacitance	10 pF for input/output
Insulation Resistance	1000 MOhm at 500 V DC
Local Signalling	LED (green) for input status
Minimum Switching Voltage	4 V DC turn-on
Maximum Switching Voltage	1 V DC turn-off
Input Current	8...11 mA
Solid State Output Type	Mosfet output DC switching
Load Current	0.0025...6 A
Transient Overvoltage	60 V
Surge Current	60 A for 10 ms
Maximum Voltage Drop	<0.6 V on-state
Resistance	0.1 Ohm on-state
Maximum Leakage Current	0.1 mA off-state
Response Time	0.6 ms (turn-on) 0.3 ms (turn-off)

Miễn trừ trách nhiệm: Tài liệu này không nhằm thay thế và không được sử dụng để xác định tính phù hợp hoặc độ tin cậy của các sản phẩm này cho các ứng dụng người dùng cụ thể

Overvoltage Category	III
Width	11 mm
Height	90.3 mm
Depth	83.7 mm
Net Weight	0.05 kg

Environment

Flame Retardance	V0 conforming to UL 94
Dielectric Strength	4 kV DC for input/output 4 kV DC for input or output to case
Pollution Degree	2
Standards	IEC 61000 IEC 62314 IEC 60950-1
Product Certifications	UL CSA
Marking	CE
Ip Degree Of Protection	IP20
Ambient Air Temperature For Operation	-30...80 °C
Ambient Air Temperature For Storage	-30...100 °C

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	2 cm
Package 1 Width	9 cm
Package 1 Length	9 cm
Package 1 Weight	61 g
Unit Type Of Package 2	S02
Number Of Units In Package 2	96
Package 2 Height	15 cm
Package 2 Width	30 cm
Package 2 Length	40 cm
Package 2 Weight	6.26 kg

Bền vững

Nhãn **Green Premium™** là cam kết của Schneider Electric trong việc cung cấp sản phẩm với hiệu suất môi trường tốt nhất. Green Premium cam kết tuân thủ các quy định mới nhất, minh bạch về tác động môi trường, cũng như các sản phẩm tuần hoàn và CO₂ thấp.

Hướng dẫn đánh giá tính bền vững của sản phẩm là tài liệu kỹ thuật phổ thông giúp làm rõ các tiêu chuẩn nhãn sinh thái toàn cầu và cách diễn giải việc khai báo môi trường.

[Tìm hiểu thêm về Green Premium >](#)

[Hướng dẫn đánh giá về sự bền vững của sản phẩm >](#)



Minh bạch RoHS/REACH

Hiệu suất sức khỏe


 Mercury Free

 Rohs Exemption Information [Yes](#)

Chứng nhận & Tiêu chuẩn


Reach Regulation	REACH Declaration
Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope)
China Rohs Regulation	China RoHS declaration
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information

Dimensions

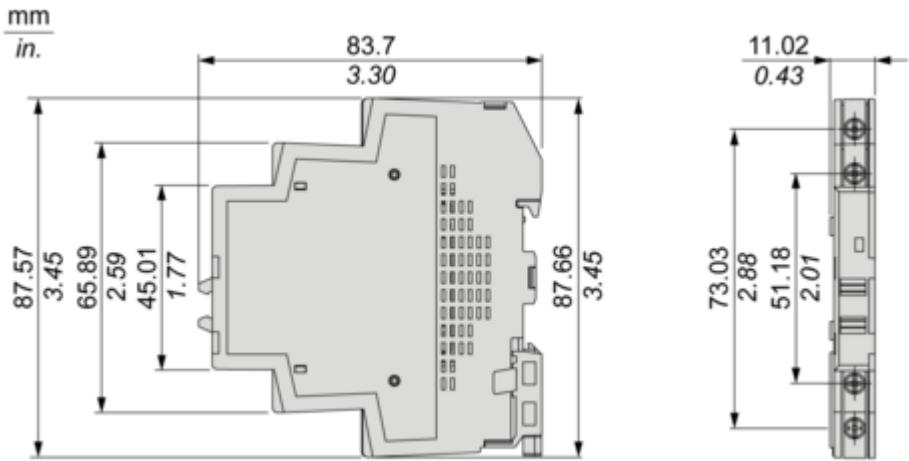

Performance Curves

Derating Curves

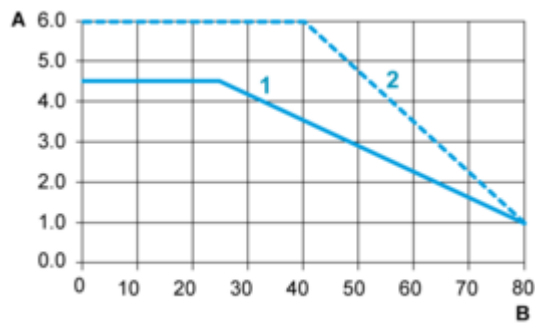

- A : Load Current (Amperes)
B : Ambient Temperature (°C)
1 : Multiple units, no minimum spacing between components
2 : Installed single unit, distance to adjacent components more than 11 mm