

Bảng thông số sản phẩm

Thông số kỹ thuật



Monolithic pre wired tower light,
Harmony XVC, plastic, red orange
green, 60mm, tube mounting,
steady or flashing, buzzer, IP23,
24V AC DC

XVC6B35S

Main

Range Of Product	Harmony XVC6
Product Or Component Type	Complete pre-wired monolithic tower light
Beacon Or Indicator Bank Unit Type	3 illuminated units
Sound Signalling	Buzzer
Mounting Diameter	60 mm
Component Name	XVC
Light Source	LED steady or flashing red LED steady or flashing orange LED steady or flashing green
[Us] Rated Supply Voltage	24 V
Supply Circuit Type	AC/DC
Noise Level	70...85 dB (continuous or intermittent tone) at 1 m

Complementary

Material	Polycarbonate: illuminated unit ABS (acrylonitrile butadiene-styrene): base unit PBT + ABS (UL94HB): top cover STK (chromium-plated): support tube
Product Mounting	On support tube, 22 mm
Cable Cross Section	0.33 mm²
Awg Gauge	AWG 22
Cable Length	550 mm
Marking	CE
[Uimp] Rated Impulse Withstand Voltage	0.8 kV
Current Consumption	115 mA
Fundamental Frequency	2.23 kHz
Flashing Frequency	1 Hz
Net Weight	0.98 kg
Height	563.1 mm

Environment

Standards	EN/IEC 61000-6-3 EN/IEC 61000-6-2 EN/IEC 61000-6-4
-----------	--

Miễn trừ trách nhiệm: Tài liệu này không nhằm thay thế và không được sử dụng để xác định tính phù hợp hoặc độ tin cậy của các sản phẩm này cho các ứng dụng người dùng cụ thể

Product Certifications	UL
Protective Treatment	TC
Ambient Air Temperature For Storage	-35...70 °C
Ambient Air Temperature For Operation	-10...50 °C
Electrical Shock Protection Class	Class I conforming to EN/IEC 61140
Ip Degree Of Protection	IP23 vertical surface installation conforming to EN/IEC 60529

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	9.000 cm
Package 1 Width	74.900 cm
Package 1 Length	9.000 cm
Package 1 Weight	900.000 g
Unit Type Of Package 2	P06
Number Of Units In Package 2	10
Package 2 Height	75.000 cm
Package 2 Width	60.000 cm
Package 2 Length	80.000 cm
Package 2 Weight	22.110 kg

Contractual warranty

Warranty	18 months
----------	-----------

Bền vững

Nhãn **Green Premium™** là cam kết của Schneider Electric trong việc cung cấp sản phẩm với hiệu suất môi trường tốt nhất. Green Premium cam kết tuân thủ các quy định mới nhất, minh bạch về tác động môi trường, cũng như các sản phẩm tuần hoàn và CO₂ thấp.

Hướng dẫn đánh giá tính bền vững của sản phẩm là tài liệu kỹ thuật phổ thông giúp làm rõ các tiêu chuẩn nhãn sinh thái toàn cầu và cách diễn giải việc khai báo môi trường.

[Tìm hiểu thêm về Green Premium >](#)

[Hướng dẫn đánh giá về sự bền vững của sản phẩm >](#)



Minh bạch

Hiệu suất sức khỏe



Mercury Free



Rohs Exemption Information

[Yes](#)

Eu Rohs Directive

Pro-active compliance (Product out of EU RoHS legal scope)

China Rohs Regulation

[China RoHS declaration](#)

Environmental Disclosure

[Product Environmental Profile](#)

Circularity Profile


[End of Life Information](#)

Dimensions Drawings

Pre-assembled and Pre-wired Tower Light with Support Tube Mounting

Dimensions

Below drawing shows the maximum configuration of the product. Select the number of stages according to the product characteristics in order to get b1 dimension.

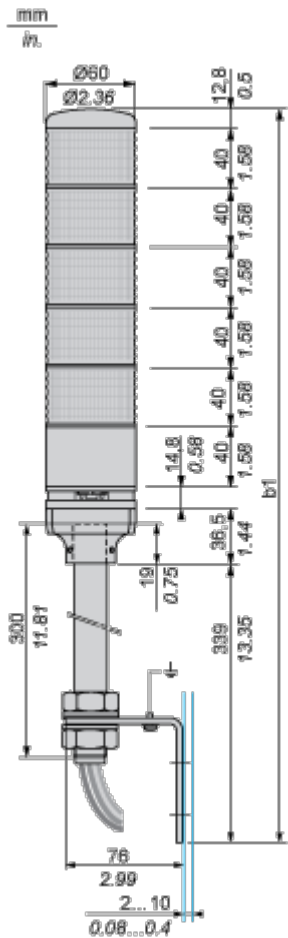

No. of illuminated units	b1 With buzzer (mm)	b1 With buzzer (in.)
1 stage	483.1	19.02
2 stages	523.1	20.59
3 stages	563.1	22.17
4 stages	603.1	23.74
5 stages	643.1	25.32

Mounting and Clearance

Pre-assembled and Pre-wired Tower Light

Support Tube Mounting

