


Product data sheet

Specifications

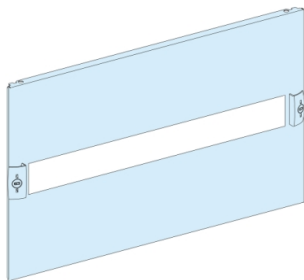

MODULAR FRONT PLATE WIDTH 600/650 4M

03204

! Discontinued on: Apr 25, 2023

! Discontinued

Main

Range	Prisma
Range Of Product	Prisma G Prisma P
Product Or Component Type	Front plate
Accessory / Separate Part Category	Installation accessory
Range Compatibility	Prisma Prisma G enclosure Prisma Prisma P cubicle Prisma Prisma Pack 250 enclosure
Type Of Front Plate	Cut-out Modular
Installed Device	Acti 9: fixed modular device Multi9: fixed modular device Vigilohm: IM20 Vigilohm: IM20H ComPact: fixed INS100 - control: direct front rotary handle - vertical installation ComPact: fixed INS125 - control: direct front rotary handle - vertical installation ComPact: fixed INS160 - control: direct front rotary handle - vertical installation ComPact: fixed INS40 - control: direct front rotary handle - vertical installation ComPact: fixed INS63 - control: direct front rotary handle - vertical installation Vigilohm: IM10 Vigilohm: IM10H
Poles Description	1 x 3P: modular rail support: INS100 vertical installation 1 x 4P: modular rail support: INS100 vertical installation 1 x 3P: modular rail support: INS125 vertical installation 1 x 4P: modular rail support: INS125 vertical installation 1 x 3P: modular rail support: INS160 vertical installation 1 x 4P: modular rail support: INS160 vertical installation 1 x 3P: modular rail support: INS40 vertical installation 1 x 4P: modular rail support: INS40 vertical installation 1 x 3P: modular rail support: INS63 vertical installation 1 x 4P: modular rail support: INS63 vertical installation

Complementary

Enclosure/Cubicle Description	Floor-standing enclosure - width 600 mm Wall-mounted enclosure - width 600 mm Cubicle - width 650 mm depth 400 mm Pack enclosure - width 555 mm Pack enclosure - width 600 mm
Connection Position	Direct connection
9 Mm Pitches	48
Number Of 18 Mm Modules Per Row	24
Number Of Vertical Modules [50 Mm]	4
Standards	IEC 61439-2 IEC 61439-1

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Product Certifications	ASEFA
Material	Steel
Surface Finish	Matt Smooth
Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9001)
Height	200 mm
Width	500 mm
Net Weight	0.72 kg
Quantity Per Set	Set of 1

Functional Unit	650 mm 400 mm Prisma P cubicle Vigilohm 4 4
	600 mm Prisma G floor-standing enclosure ComPact INS100 fixed direct front rotary handle vertical 3P 1 direct 4
	600 mm Prisma G wall-mounted enclosure ComPact INS100 fixed direct front rotary handle vertical 3P 1 direct 4
	600 mm Prisma G floor-standing enclosure ComPact INS100 fixed direct front rotary handle vertical 4P 1 direct 4
	600 mm Prisma G wall-mounted enclosure ComPact INS100 fixed direct front rotary handle vertical 4P 1 direct 4
	650 mm 400 mm Prisma P cubicle ComPact INS100 fixed direct front rotary handle vertical 3P 1 direct 4
	650 mm 400 mm Prisma P cubicle ComPact INS100 fixed direct front rotary handle vertical 4P 1 direct 4
	600 mm Prisma G floor-standing enclosure ComPact INS125 fixed direct front rotary handle vertical 3P 1 direct 4
	600 mm Prisma G wall-mounted enclosure ComPact INS125 fixed direct front rotary handle vertical 3P 1 direct 4
	600 mm Prisma G floor-standing enclosure ComPact INS125 fixed direct front rotary handle vertical 4P 1 direct 4
	600 mm Prisma G wall-mounted enclosure ComPact INS125 fixed direct front rotary handle vertical 4P 1 direct 4
	650 mm 400 mm Prisma P cubicle ComPact INS125 fixed direct front rotary handle vertical 3P 1 direct 4
	650 mm 400 mm Prisma P cubicle ComPact INS125 fixed direct front rotary handle vertical 4P 1 direct 4
	600 mm Prisma G floor-standing enclosure ComPact INS160 fixed direct front rotary handle vertical 3P 1 direct 4
	600 mm Prisma G wall-mounted enclosure ComPact INS160 fixed direct front rotary handle vertical 3P 1 direct 4
	600 mm Prisma G floor-standing enclosure ComPact INS160 fixed direct front rotary handle vertical 4P 1 direct 4
	600 mm Prisma G wall-mounted enclosure ComPact INS160 fixed direct front rotary handle vertical 4P 1 direct 4
	650 mm 400 mm Prisma P cubicle ComPact INS160 fixed direct front rotary handle vertical 3P 1 direct 4
	650 mm 400 mm Prisma P cubicle ComPact INS160 fixed direct front rotary handle vertical 4P 1 direct 4
	600 mm Prisma G floor-standing enclosure ComPact INS40 fixed direct front rotary handle vertical 3P 1 direct 4
	600 mm Prisma G wall-mounted enclosure ComPact INS40 fixed direct front rotary handle vertical 3P 1 direct 4
	600 mm Prisma G floor-standing enclosure ComPact INS40 fixed direct front rotary handle vertical 4P 1 direct 4
	600 mm Prisma G wall-mounted enclosure ComPact INS40 fixed direct front rotary handle vertical 4P 1 direct 4
	650 mm 400 mm Prisma P cubicle ComPact INS40 fixed direct front rotary handle vertical 3P 1 direct 4
	650 mm 400 mm Prisma P cubicle ComPact INS40 fixed direct front rotary handle vertical 4P 1 direct 4
	600 mm Prisma G floor-standing enclosure ComPact INS63 fixed direct front rotary handle vertical 3P 1 direct 4
	600 mm Prisma G wall-mounted enclosure ComPact INS63 fixed direct front rotary handle vertical 3P 1 direct 4
	600 mm Prisma G floor-standing enclosure ComPact INS63 fixed direct front rotary handle vertical 4P 1 direct 4
	600 mm Prisma G wall-mounted enclosure ComPact INS63 fixed direct front rotary handle vertical 4P 1 direct 4
	650 mm 400 mm Prisma P cubicle ComPact INS63 fixed direct front rotary handle vertical 3P 1 direct 4
	650 mm 400 mm Prisma P cubicle ComPact INS63 fixed direct front rotary handle vertical 4P 1 direct 4
	600 mm Prisma G floor-standing enclosure Acti 9 modular device fixed 48 direct 4
	600 mm Prisma G wall-mounted enclosure Acti 9 modular device fixed 48 direct 4
	650 mm 400 mm Prisma P cubicle Acti 9 modular device fixed 48 direct 4
	600 mm Prisma G floor-standing enclosure Multi9 modular device fixed 48 direct 4
	600 mm Prisma G wall-mounted enclosure Multi9 modular device fixed 48 direct 4
	650 mm 400 mm Prisma P cubicle Multi9 modular device fixed 48 direct 4
	600 mm Prisma Pack 250 Pack enclosure Multi9 modular device fixed 48 direct 6

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	3.000 cm
Package 1 Width	21.000 cm

Package 1 Length	52.000 cm
Package 1 Weight	726.000 g
Unit Type Of Package 2	BB1
Number Of Units In Package 2	10
Package 2 Height	17.000 cm
Package 2 Width	22.000 cm
Package 2 Length	53.000 cm
Package 2 Weight	7.467 kg
Unit Type Of Package 3	P12
Number Of Units In Package 3	360
Package 3 Height	82.000 cm
Package 3 Width	80.000 cm
Package 3 Length	120.000 cm
Package 3 Weight	265.440 kg

Sustainability

Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓ Reach Free Of Svhc

✓ Toxic Heavy Metal Free

✓ Mercury Free

✓ Rohs Exemption Information [Yes](#)

✓ Halogen Free Plastic Parts Product

Certifications & Standards

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
--------------------------	---

China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
------------------------------	---

Environmental Disclosure	Product Environmental Profile
---------------------------------	---