


# Product data sheet

Specifications

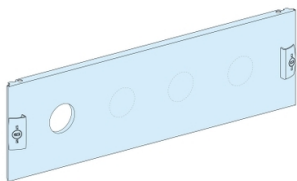

## FRONT PLATE INF32HZ 3/4P- INF32-40 V4P WIDTH 600/650 3M

03313

⚠ Discontinued on: Nov 12, 2020

⚠ Discontinued

### Main

Range	Prisma
Range Of Product	Prisma G Prisma P
Product Or Component Type	Front plate
Accessory / Separate Part Category	Installation accessory
Range Compatibility	Prisma Prisma G enclosure Prisma Prisma P cubicle
Type Of Front Plate	Cut-out
Installed Device	FuPact: fixed INF32 - control: extended rotary handle - vertical installation FuPact: fixed INF40 - control: extended rotary handle - vertical installation FuPact: fixed INF32 - control: extended rotary handle - horizontal installation FuPact: fixed INF40 - control: extended rotary handle - horizontal installation
Poles Description	1 x 3P: mounting plate support: INF32 horizontal installation 1 x 4P: mounting plate support: INF32 horizontal installation 1 x 3P: mounting plate support: INF40 horizontal installation 1 x 4P: mounting plate support: INF40 horizontal installation 3 x 4P: mounting plate support: INF32 vertical installation 3 x 4P: mounting plate support: INF40 vertical installation
Operating Position	Vertical Horizontal

### Complementary

Enclosure/Cubicle Description	Floor-standing enclosure - width 600 mm Wall-mounted enclosure - width 600 mm Cubicle - width 650 mm depth 400 mm
Connection Position	Direct connection
Number Of Vertical Modules [50 Mm]	3
Standards	IEC 61439-2 IEC 61439-1
Product Certifications	ASEFA
Material	Steel
Surface Finish	Matt Smooth
Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9001)
Height	150 mm
Width	500 mm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Net Weight	0.66 kg
Quantity Per Set	Set of 1
Functional Unit	600 mm Prisma G floor-standing enclosure FuPact INF32 fixed extended rotary handle horizontal 3P 1 direct 3 600 mm Prisma G wall-mounted enclosure FuPact INF32 fixed extended rotary handle horizontal 3P 1 direct 3 600 mm Prisma G floor-standing enclosure FuPact INF32 fixed extended rotary handle horizontal 4P 1 direct 3 600 mm Prisma G wall-mounted enclosure FuPact INF32 fixed extended rotary handle horizontal 4P 1 direct 3 600 mm Prisma G floor-standing enclosure FuPact INF32 fixed extended rotary handle vertical 4P 3 direct 3 600 mm Prisma G wall-mounted enclosure FuPact INF32 fixed extended rotary handle vertical 4P 3 direct 3 650 mm 400 mm Prisma P cubicle FuPact INF32 fixed extended rotary handle horizontal 3P 1 direct 3 650 mm 400 mm Prisma P cubicle FuPact INF32 fixed extended rotary handle horizontal 4P 1 direct 3 650 mm 400 mm Prisma P cubicle FuPact INF32 fixed extended rotary handle vertical 4P 3 direct 3 600 mm Prisma G floor-standing enclosure FuPact INF40 fixed extended rotary handle vertical 4P 3 direct 3 600 mm Prisma G wall-mounted enclosure FuPact INF40 fixed extended rotary handle vertical 4P 3 direct 3 650 mm 400 mm Prisma P cubicle FuPact INF40 fixed extended rotary handle horizontal 3P 1 direct 3 650 mm 400 mm Prisma P cubicle FuPact INF40 fixed extended rotary handle horizontal 4P 1 direct 3 650 mm 400 mm Prisma P cubicle FuPact INF40 fixed extended rotary handle vertical 4P 3 direct 3

## Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	3 cm
Package 1 Width	16 cm
Package 1 Length	52 cm
Package 1 Weight	670 g

## Sustainability

**Green Premium™ label** is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency   RoHS/REACH

## Well-being performance

✓ Reach Free Of Svhc

✓ Toxic Heavy Metal Free

✓ Mercury Free

✓ Rohs Exemption Information   [Yes](#)

✓ Halogen Free Plastic Parts Product

## Certifications & Standards

<b>Eu Rohs Directive</b>	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
--------------------------	---

<b>China Rohs Regulation</b>	<a href="#">China RoHS declaration</a> Pro-active China RoHS declaration (out of China RoHS legal scope)
------------------------------	---

<b>Environmental Disclosure</b>	<a href="#">Product Environmental Profile</a>
---------------------------------	---