


Product data sheet

Specifications

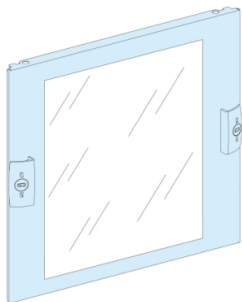

TRANSPARENT FRONT PLATE W300 4M

03352

⚠ Discontinued on: Apr 25, 2023

⚠ Discontinued

Main

Range	Prisma
Range Of Product	Prisma G Prisma P
Product Or Component Type	Front plate
Accessory / Separate Part Category	Installation accessory
Range Compatibility	Prisma Prisma G duct Prisma Prisma P cubicle
Type Of Front Plate	Transparent
Installed Device	TeSys: fixed TeSys U - horizontal installation TeSys: fixed GV2 + D or K contactors <= 40 A - horizontal installation
Poles Description	4 x 3P: modular rail support: GV2 + D or K contactors <= 40 A horizontal installation 4 x 3P: modular rail support: TeSys U horizontal installation
Operating Position	Horizontal

Complementary

Enclosure/Cubicle Description	Floor-standing duct - width 300 mm Wall-mounted duct - width 300 mm Cubicle duct - width 400 mm depth 400 mm
Connection Position	Direct connection
Number Of Vertical Modules [50 Mm]	4
Standards	IEC 61439-2 IEC 61439-1
Product Certifications	ASEFA
Material	Glass
Surface Finish	Smooth Matt
Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9001)
Height	200 mm
Width	300 mm
Net Weight	0.54 kg
Quantity Per Set	Set of 1

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Functional Unit	300 mm Prisma G floor-standing duct TeSys GV2 + D or K contactors <= 40 A fixed horizontal 3P 4 direct 5 300 mm Prisma G wall-mounted duct TeSys GV2 + D or K contactors <= 40 A fixed horizontal 3P 4 direct 5 400 mm 400 mm Prisma P cubicle 300 mm Prisma G floor-standing duct TeSys TeSys U fixed horizontal 3P 4 direct 5 300 mm Prisma G wall-mounted duct TeSys TeSys U fixed horizontal 3P 4 direct 5 300 mm Prisma G floor-standing duct TeSys TeSys U fixed horizontal 3P 4 direct 4 300 mm Prisma G wall-mounted duct TeSys TeSys U fixed horizontal 3P 4 direct 4
-----------------	--

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	3.0 cm
Package 1 Width	20.0 cm
Package 1 Length	25.0 cm
Package 1 Weight	540.0 g
Unit Type Of Package 2	S03
Number Of Units In Package 2	8
Package 2 Height	30.0 cm
Package 2 Width	30.0 cm
Package 2 Length	40.0 cm
Package 2 Weight	5.523 kg

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓ Reach Free Of Svhc

✓ Toxic Heavy Metal Free

✓ Mercury Free

✓ Rohs Exemption Information [Yes](#)

Certifications & Standards

Eu Rohs Directive Pro-active compliance (Product out of EU RoHS legal scope)
[EU RoHS Declaration](#)

China Rohs Regulation [China RoHS declaration](#)
Pro-active China RoHS declaration (out of China RoHS legal scope)

Environmental Disclosure [Product Environmental Profile](#)