


Product data sheet

Specifications

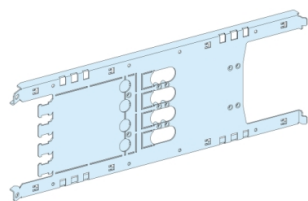

MOUNTING PLATE VIGI NSX/CVS PLUGIN TOGGLE/ROT/MOT - 4P 250A HORIZONTAL WIDTH 650

03414

⚠ Discontinued on: Apr 25, 2023

⚠ Discontinued

Main

Range	Prisma
Range Of Product	Prisma P
Product Or Component Type	Mounting plate
Accessory / Separate Part Category	Installation accessory
Range Compatibility	Prisma Prisma P cubicle
Installation Description	Cubicle - width 650 mm depth 400 mm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Installed Device	EasyPact: fixed CVS100...160 without earth leakage protection - control: direct front rotary handle - horizontal installation EasyPact: fixed CVS250 without earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: fixed NSX100...160 without earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: fixed NSX250 without earth leakage protection - control: direct front rotary handle - horizontal installation EasyPact: fixed CVS100...160 with earth leakage protection - control: direct front rotary handle - horizontal installation EasyPact: fixed CVS250 with earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: fixed NSX100...160 with earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: fixed NSX250 with earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: fixed NSX100...160 without earth leakage protection - control: motor mechanism - horizontal installation ComPact: plug-in NSX100...160 without earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX250 without earth leakage protection - control: motor mechanism - horizontal installation ComPact: plug-in NSX250 without earth leakage protection - control: toggle - horizontal installation ComPact: plug-in NSX100...160 without earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: plug-in NSX100...160 without earth leakage protection - control: motor mechanism - horizontal installation ComPact: plug-in NSX250 without earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: plug-in NSX250 without earth leakage protection - control: motor mechanism - horizontal installation ComPact: plug-in NSX100...160 with earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX100...160 with earth leakage protection - control: motor mechanism - horizontal installation ComPact: plug-in NSX100...160 with earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: plug-in NSX100...160 with earth leakage protection - control: motor mechanism - horizontal installation ComPact: plug-in NSX250 with earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX250 with earth leakage protection - control: motor mechanism - horizontal installation ComPact: plug-in NSX250 with earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: plug-in NSX250 with earth leakage protection - control: motor mechanism - horizontal installation
Poles Description	1 x 4P: fixed CVS100...160 horizontal installation 1 x 4P: fixed CVS250 horizontal installation 1 x 4P: fixed NSX100...160 horizontal installation 1 x 4P: fixed NSX250 horizontal installation 1 x 4P: plug-in NSX100...160 horizontal installation 1 x 4P: plug-in NSX250 horizontal installation
Number Of Vertical Modules [50 Mm]	4 module(s): CVS100...160 without earth leakage protection , direct in 650 mm Widecubicle 4 module(s): CVS250 without earth leakage protection , direct in 650 mm Widecubicle 4 module(s): NSX100...160 without earth leakage protection , direct in 650 mm Widecubicle 4 module(s): NSX250 without earth leakage protection , direct in 650 mm Widecubicle 4 module(s): CVS100...160 with earth leakage protection , direct in 650 mm Widecubicle 4 module(s): CVS250 with earth leakage protection , direct in 650 mm Widecubicle 4 module(s): NSX100...160 with earth leakage protection , direct in 650 mm Widecubicle 4 module(s): NSX250 with earth leakage protection , direct in 650 mm Widecubicle
Standards	IEC 61439-2
Product Certifications	ASEFA

Complementary

Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
----------------------	--

Surface Finish	Smooth Matt
Colour	White (RAL 9001)
Width	650 mm
Height	200 mm
Net Weight	2.36 kg
Functional Unit	650 mm 400 mm Prisma P cubicle EasyPact CVS100...160 without fixed direct front rotary handle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle EasyPact CVS250 without fixed direct front rotary handle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed direct front rotary handle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed motor mechanism horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without plug-in direct front rotary handle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without plug-in motor mechanism horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without plug-in toggle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX250 without fixed direct front rotary handle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX250 without fixed motor mechanism horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX250 without plug-in direct front rotary handle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX250 without plug-in motor mechanism horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX250 without plug-in toggle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle EasyPact CVS100...160 with fixed direct front rotary handle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle EasyPact CVS250 with fixed direct front rotary handle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with fixed direct front rotary handle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with fixed motor mechanism horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with plug-in direct front rotary handle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with plug-in motor mechanism horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with plug-in toggle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX250 with fixed direct front rotary handle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX250 with fixed motor mechanism horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX250 with plug-in direct front rotary handle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX250 with plug-in motor mechanism horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX250 with plug-in toggle horizontal 4P 1 direct 4 12.5 mm

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	3.000 cm
Package 1 Width	20.100 cm
Package 1 Length	57.200 cm
Package 1 Weight	2.500 kg
Unit Type Of Package 2	S04
Number Of Units In Package 2	8

Package 2 Height	30.000 cm
Package 2 Width	40.000 cm
Package 2 Length	60.000 cm
Package 2 Weight	20.850 kg
Unit Type Of Package 3	P12
Number Of Units In Package 3	64
Package 3 Height	75.000 cm
Package 3 Width	80.000 cm
Package 3 Length	120.000 cm
Package 3 Weight	178.800 kg

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Well-being performance



Mercury Free



RoHS Exemption Information

[Yes](#)



Halogen Free Plastic Parts Product

Certifications & Standards

Eu RoHS Directive

Pro-active compliance (Product out of EU RoHS legal scope)

[EU RoHS Declaration](#)

China RoHS Regulation

[China RoHS declaration](#)

Product out of China RoHS scope. Substance declaration for your information

Environmental Disclosure

[Product Environmental Profile](#)

Circularity Profile

[End of Life Information](#)