


Product data sheet

Specifications

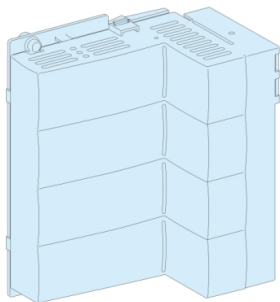

POWER SUPPLY BLOCK NSX/ CVS/INS-INV 400 4P

04070

⚠ Discontinued on: Jan 20, 2022

⚠ Discontinued

Main

Range	Lineryg
Range Of Product	Lineryg
Product Or Component Type	Power supply block
Product Name	Lineryg BW
Product Name	Prisma Prisma P enclosure Prisma Prisma G enclosure Lineryg Lineryg BW busbar
Accessory / Separate Part Category	Current distribution accessory
Provided Equipment	With connection
Standards	IEC 61439-1, inside Prisma IEC 61439-2, inside Prisma
Product Certifications	ASEFA

Complementary

Cubicle-Device Connection	Lineryg BW busbar
Poles Description	4P
Installation Description	Cubicle - width 650 mm Floor-standing enclosure - width 850 mm Floor-standing enclosure + duct - width 600 + 300 mm Wall-mounted enclosure + duct - width 600 + 300 mm
Installed Device	ComPact: fixed NSX400 without earth leakage protection - control: toggle horizontal installation ComPact: fixed INS320...400 - control: direct front rotary handle horizontal installation ComPact: fixed INV320...400 - control: direct front rotary handle horizontal installation EasyPact: fixed CVS400 without earth leakage protection - control: toggle horizontal installation
[Ie] Rated Operational Current	400 A
[In] Rated Current	400 A
Net Weight	2.68 kg
Quantity Per Set	Set of 1

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Functional Unit

[illegible]

rotary handle horizontal 4P 1 direct with long terminal shield 6
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX400 without
fixed toggle horizontal 3P 1 connection block 9
600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX400 without
fixed toggle horizontal 3P 1 connection block 9
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX400 without
fixed toggle horizontal 4P 1 connection block 9
600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX400 without
fixed toggle horizontal 4P 1 connection block 9
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX400 without
fixed toggle horizontal 3P 1 connection block 6
600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX400 without
fixed toggle horizontal 3P 1 connection block 6
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX400 without
fixed toggle horizontal 4P 1 connection block 6
600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX400 without
fixed toggle horizontal 4P 1 connection block 6
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX400 without
fixed toggle horizontal 3P 1 direct with long terminal shield 9
600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX400 without
fixed toggle horizontal 3P 1 direct with long terminal shield 9
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX400 without
fixed toggle horizontal 4P 1 direct with long terminal shield 9
600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX400 without
fixed toggle horizontal 4P 1 direct with long terminal shield 9
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX400 without
fixed toggle horizontal 3P 1 direct with long terminal shield 6
600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX400 without
fixed toggle horizontal 3P 1 direct with long terminal shield 6
600 + 300 mm Prisma G floor-standing enclosure + duct ComPact NSX400 without
fixed toggle horizontal 4P 1 direct with long terminal shield 6
600 + 300 mm Prisma G wall-mounted enclosure + duct ComPact NSX400 without
fixed toggle horizontal 4P 1 direct with long terminal shield 6

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓ Reach Free Of Svhc

✓ Toxic Heavy Metal Free

✓ Mercury Free

✓ Rohs Exemption Information [Yes](#)

Certifications & Standards

Eu Rohs Directive Pro-active compliance (Product out of EU RoHS legal scope)
[EU RoHS Declaration](#)

China Rohs Regulation [China RoHS declaration](#)
Pro-active China RoHS declaration (out of China RoHS legal scope)

Environmental Disclosure [Product Environmental Profile](#)