


Product data sheet

Specifications

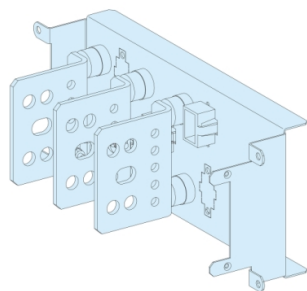

UNIVERSAL CONNECTION TRANSFERT IN DUCT 250A 3P

04429

⚠ Discontinued on: Apr 25, 2023

⚠ Discontinued

Main

Range	Prisma
Range Of Product	Prisma P
Product Or Component Type	Connection transfer assembly
Product Name	Prisma Prisma P enclosure
Accessory / Separate Part Category	Current distribution accessory
Standards	IEC 61439-2 IEC 61439-1
Product Certifications	ASEFA

Complementary

Cubicle-Device Connection	connection transfer assembly
Poles Description	3P
Installation Description	Cubicle - width 650 mm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

ComPact: plug-in NSX100...160 with earth leakage protection - control: toggle
horizontal installation
ComPact: plug-in NSX250 with earth leakage protection - control: toggle horizontal
installation

[Ie] Rated Operational Current	250 A
[In] Rated Current	250 A
Busbar Cross Section	20 x 3 mm
Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Surface Finish	Smooth Matt
Height	150 mm
Width	350 mm
Net Weight	2.84 kg
Quantity Per Set	Set of 1

Functional Unit	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with fixed toggle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX250 with fixed toggle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed direct front rotary handle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed motor mechanism horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without plug-in direct front rotary handle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without plug-in motor mechanism horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without drawout direct front rotary handle horizontal 3P 1 direct 5
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without drawout motor mechanism horizontal 3P 1 direct 5
	650 mm 400 mm Prisma P cubicle ComPact NSX250 without fixed direct front rotary handle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX250 without fixed motor mechanism horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX250 without plug-in direct front rotary handle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX250 without plug-in motor mechanism horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX250 without drawout direct front rotary handle horizontal 3P 1 direct 5
	650 mm 400 mm Prisma P cubicle ComPact NSX250 without drawout motor mechanism horizontal 3P 1 direct 5
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with fixed direct front rotary handle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with fixed motor mechanism horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with plug-in direct front rotary handle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with plug-in motor mechanism horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with drawout direct front rotary handle horizontal 3P 1 direct 5
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with drawout motor mechanism horizontal 3P 1 direct 5
	650 mm 400 mm Prisma P cubicle ComPact NSX250 with fixed direct front rotary handle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX250 with fixed motor mechanism horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX250 with plug-in direct front rotary handle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX250 with plug-in motor mechanism horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX250 with drawout direct front rotary handle horizontal 3P 1 direct 5
	650 mm 400 mm Prisma P cubicle ComPact NSX250 with drawout motor mechanism horizontal 3P 1 direct 5
	650 mm 400 mm Prisma P cubicle EasyPact CVS100...160 without fixed toggle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle EasyPact CVS100...160 without fixed direct front rotary handle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle EasyPact CVS250 without fixed toggle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle EasyPact CVS250 without fixed direct front rotary handle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without plug-in toggle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without drawout toggle horizontal 3P 1 direct 5
	650 mm 400 mm Prisma P cubicle ComPact NSX250 without plug-in toggle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX250 without drawout toggle horizontal 3P 1 direct 5
	650 mm 400 mm Prisma P cubicle EasyPact CVS100...160 with fixed toggle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle EasyPact CVS100...160 with fixed direct front rotary handle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle EasyPact CVS250 with fixed toggle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle EasyPact CVS250 with fixed direct front rotary handle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with plug-in toggle horizontal 3P 1 direct 3
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with drawout toggle horizontal 3P 1 direct 5

650 mm 400 mm Prisma P cubicle ComPact NSX250 with plug-in toggle horizontal
3P 1 direct 3
650 mm 400 mm Prisma P cubicle ComPact NSX250 with drawout toggle horizontal
3P 1 direct 5

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	16.0 cm
Package 1 Width	27.5 cm
Package 1 Length	40.0 cm
Package 1 Weight	2.85 kg
Unit Type Of Package 2	P12
Number Of Units In Package 2	45
Package 2 Height	93.0 cm
Package 2 Width	80.0 cm
Package 2 Length	120.0 cm
Package 2 Weight	140.25 kg

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓	Reach Free Of Svhc	
✓	Toxic Heavy Metal Free	
✓	Mercury Free	
✓	Rohs Exemption Information	Yes

Certifications & Standards

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information