


Product data sheet

Specifications

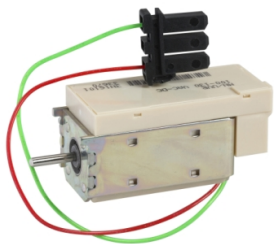

Standard opening voltage release
MX, ComPacT NS630b/NS3200,
fixed, 200/250V AC/DC, spare part

33662

Main

| | |
|-------------------------------|---|
| Range | ComPacT |
| Range Of Product | ComPacT NS630b...1600 new generation ComPacT NS1600b...3200 new generation |
| Device Short Name | MX |
| Product Or Component Type | Voltage release |
| Device Application | Control |
| Voltage Release Type | Opening coil Instantaneous voltage release |
| Control Type | Standard |
| [Uc] Control Circuit Voltage | 200...250 V AC 50/60 Hz 200...250 V DC |
| Circuit Breaker Mounting Mode | Fixed |
| Range Compatibility | ComPact ComPact NS630b...1600 ComPact ComPact NS1600b...3200 |

Complementary

| | |
|------------------------------------|---|
| Operating Threshold | 0.7...1.1 x Un opening |
| Response Time | 50 ms +/- 10 % for Compact NS630b...1600 50 ms +/- 10 % for Compact NS1600b...3200 55 ms +/- 10 % for MasterPact NT 70 ms +/- 10 % for MasterPact NW |
| Supply Holding Power | 4.5 VA |
| Accessory / Separate Part Category | Spare part for MasterPact NT Spare part for MasterPact NW Spare part for ComPacT NS630b...1600 new generation Spare part for ComPacT NS1600b...3200 new generation |

Packing Units

| | |
|------------------------------|---------|
| Unit Type Of Package 1 | PCE |
| Number Of Units In Package 1 | 1 |
| Package 1 Height | 3.3 cm |
| Package 1 Width | 6.0 cm |
| Package 1 Length | 8.2 cm |
| Package 1 Weight | 150.0 g |
| Unit Type Of Package 2 | BB1 |
| Number Of Units In Package 2 | 10 |

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

| | |
|------------------------------|-----------|
| Package 2 Height | 9.0 cm |
| Package 2 Width | 13.2 cm |
| Package 2 Length | 18.5 cm |
| Package 2 Weight | 1.556 kg |
| Unit Type Of Package 3 | S03 |
| Number Of Units In Package 3 | 120 |
| Package 3 Height | 30.0 cm |
| Package 3 Width | 30.0 cm |
| Package 3 Length | 40.0 cm |
| Package 3 Weight | 19.303 kg |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓ Mercury Free

✓ Rohs Exemption Information [Yes](#)

Certifications & Standards

| | |
|---------------------------|--|
| Reach Regulation | REACH Declaration |
| Eu Rohs Directive | Compliant with Exemptions |
| China Rohs Regulation | China RoHS declaration Product out of China RoHS scope. Substance declaration for your information |
| Environmental Disclosure | Product Environmental Profile |
| Circularity Profile | End of Life Information |
| California Proposition 65 | WARNING: This product can expose you to chemicals including: DINP, which is known to the State of California to cause cancer, and DIDP, which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov |