


Product data sheet

Specifications

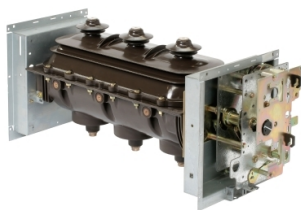

LBSKIT component Motorized 630A CIT 24VDC 7AC

3730109AU

Main

Range Of Product	LBSKit
Product Or Component Type	Switch Motor mechanism

Complementary

Rated Voltage (Ur)	12...24 kV
Rated Continuous Current (Ir)	630 A
Type Of Operator	CIT
Number Of Contacts	7
Width	375 mm

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	52.8 cm
Package 1 Width	47.9 cm
Package 1 Length	107.9 cm
Package 1 Weight	54 kg
Unit Type Of Package 2	P12
Number Of Units In Package 2	6
Package 2 Height	120 cm
Package 2 Width	112 cm
Package 2 Length	140 cm
Package 2 Weight	342 kg

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓ Mercury Free

✓ Rohs Exemption Information [Yes](#)

Certifications & Standards

Reach Regulation	REACH Declaration
Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope)
China Rohs Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information