


Product data sheet

Specifications

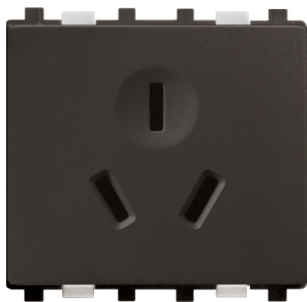

250V 10A China 3 Flat Pin Socket 2M Sized Module, Bronze

84426M10CS_BZ

⚠ Discontinued on: Sep 30, 2021

⚠ Discontinued

Main

Product Or Component Type	Power socket-outlet
Outlet Poles Configuration	2P + E China
Load Type	Resistive
Cover Plate Colour Tint	Bronze

Complementary

Device Mounting	Flush Surface
Rated Current	10 A at 250 V AC 50/60 Hz
Number Of Gangs	1 gang
Material	Polycarbonate base Polycarbonate cover
Connections - Terminals	Screw terminals
Width	46.7 mm
Height	45.8 mm
Depth	27.28 mm

Environment

Ambient Air Temperature For Storage	0...60 °C
Ambient Air Temperature For Operation	-5...40 °C
Relative Humidity	0...95 %, non-condensing (storage) 10...95 %, non-condensing (operating)
Environmental Characteristic	UV resistant indoor use
Operating Altitude	2000 m
Standards	GB 2099.1
Ip Degree Of Protection	IP20
Standards	GB 2099.1
Product Certifications	CCC

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Certifications & Standards

Eu Rohs Directive

Pro-active compliance (Product out of EU RoHS legal scope)

[EU RoHS Declaration](#)

Environmental Disclosure

[Product Environmental Profile](#)