


# Product data sheet

Specifications

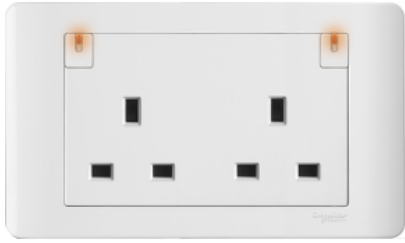

## 13A Twin Gang Switched Socket with Neon, White

E84T25N\_WE

! Discontinued on: 30 September 2020

! End-of-service on: 26 October 2020

! Discontinued

### Main

Product or component type	Power socket-outlet
Outlet poles configuration	2P + E
Load type	Resistive
Colour tint	White
Cover frame colour tint	White

### Complementary

Device mounting	Surface Flush
Local signalling	Indicator light, neon (amber)
Rated current	13 A at 250 V AC 50 Hz
Number of gangs	2 gangs
Material	Brass contact Polycarbonate base Polycarbonate grid plate Polycarbonate surround Phosphor bronze contact
Connections - terminals	Folded terminal
Width	147 mm
Height	87 mm
Depth	8 mm

### Environment

Ambient air temperature for operation	-5...40 °C
Relative humidity	0...95 %
Environmental characteristic	UV resistant indoor use
Operating altitude	2000 m
Standards	BS 1363-2 MS 589 SS 145  MS 589 SS 145 BS 1363-2

## Packing Units

Package 1 Weight	128.330 g
Package 1 Height	1.000 mm
Package 1 Width	1.000 mm
Package 1 Length	1.000 mm

## Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS declaration</a> Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	<a href="#">End of Life Information</a>

## Contractual warranty

Warranty	18 months
----------	-----------

## Recommended replacement(s)