


Product data sheet

Specifications

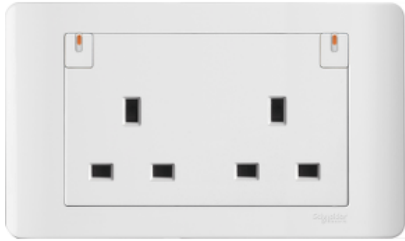

13A Twin Gang Switched Socket with Indicator, White

E84T25_WE

Main

Product or component type	Power socket-outlet
Outlet poles configuration	2P + E
Load type	Resistive
Colour tint	White
Cover frame colour tint	White

Complementary

Device mounting	Surface Flush
Local signalling	Mechanical indicator (amber)
Rated current	13 A at 250 V AC 50 Hz
Number of gangs	2 gangs
Material	Brass contact Polycarbonate base Polycarbonate grid plate Polycarbonate surround Phosphor bronze contact
Connections - terminals	Folded terminal
Width	147 mm
Height	87 mm
Depth	8 mm

Environment

Ambient air temperature for operation	-5...40 °C
Relative humidity	0...95 %
Environmental characteristic	UV resistant indoor use
Operating altitude	2000 m
Standards	BS 1363-2 MS 589 SS 145 MS 589 SS 145 BS 1363-2

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	4 cm
Package 1 Width	8.7 cm
Package 1 Length	8.7 cm
Package 1 Weight	196.09 g
Unit Type of Package 2	BB1
Number of Units in Package 2	5
Package 2 Height	15 cm
Package 2 Width	19 cm
Package 2 Length	5 cm
Package 2 Weight	980 g
Unit Type of Package 3	CAR
Number of Units in Package 3	50
Package 3 Height	21 cm
Package 3 Width	32.5 cm
Package 3 Length	50 cm
Package 3 Weight	9804.5 g

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information

Contractual warranty

Warranty	18 months
----------	-----------

Recommended replacement(s)