


Product data sheet

Specifications

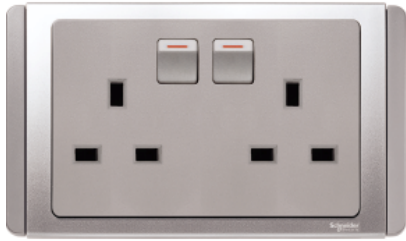

13A Twin 3 Pin Switched Socket Outlet, Grey Silver

ET3025_GS

Main

Range	Neo C-Metro
Product or component type	Power socket-outlet
Switch function	1-pole
Outlet poles configuration	3P with shutters
Outlet standard	MS 589 SS 145 BS 1363
Colour tint	Grey silver

Complementary

Wiring device mounting	Flush Surface
Rated current	13 A at 250 V AC 50/60 Hz
Material	Brass: contact Copper with silver onlay: bridge Nylon: shutter Polycarbonate: grid plate Polycarbonate: surround Steel with brass plating: screws Steel with brass plating: terminals
Load type	Resistive
Connections - terminals	Pillar terminals
Width	147 mm
Height	87 mm
Depth	18 mm

Environment

Ambient air temperature for operation	0...40 °C
Relative humidity	0...95 %
Environmental characteristic	Indoor use
Standards	BS 1363 SS 145 MS 589

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	300.0 g
Package 1 Height	2.2 cm
Package 1 Width	8.6 cm
Package 1 Length	14.6 cm

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information

Contractual warranty

Warranty	18 months
----------	-----------

Recommended replacement(s)