

Product data sheet

Specifications

Linergy FT, Comb busbar, 63A, 4 tap-offs, 54mm pitch



GV2G454

Main

| | |
|---|---|
| Range | Linergy |
| Product Name | FT |
| Device Short Name | GV2G |
| Product Or Component Type | Comb busbar |
| Accessory / Separate Part Category | Connection accessory |
| Poles Description | 3P |
| Range Compatibility | TeSys Deca TeSys GV2 TeSys K TeSys U |
| Number Of Tap-Offs | 4 |
| [Ith] Conventional Free Air Thermal Current | 63 A |
| Connection Pitch | 54 mm |

Complementary

| | |
|------------------------------|-------------|
| Mounting Location | On terminal |
| [U] Rated Insulation Voltage | 690 V |
| Length | 206 mm |
| Net Weight | 0.085 kg |

Packing Units

| | |
|------------------------------|-----------|
| Unit Type Of Package 1 | PCE |
| Number Of Units In Package 1 | 1 |
| Package 1 Height | 1.900 cm |
| Package 1 Width | 3.700 cm |
| Package 1 Length | 21.600 cm |
| Package 1 Weight | 88.000 g |
| Unit Type Of Package 2 | S01 |
| Number Of Units In Package 2 | 50 |
| Package 2 Height | 15.000 cm |
| Package 2 Width | 15.000 cm |
| Package 2 Length | 40.000 cm |
| Package 2 Weight | 4.628 kg |

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

| | |
|------------------------------|------------|
| Unit Type Of Package 3 | P06 |
| Number Of Units In Package 3 | 1600 |
| Package 3 Height | 75.000 cm |
| Package 3 Width | 60.000 cm |
| Package 3 Length | 80.000 cm |
| Package 3 Weight | 156.500 kg |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓ Reach Free Of Svhc

✓ Toxic Heavy Metal Free

✓ Mercury Free


✓ Rohs Exemption Information Yes

Certifications & Standards

| | |
|--------------------------|--|
| Reach Regulation | REACH Declaration |
| Eu Rohs Directive | Compliant EU RoHS Declaration |
| China Rohs Regulation | China RoHS declaration |
| Environmental Disclosure | Product Environmental Profile |
| Circularity Profile | End of Life Information |

Dimensions Drawings

Sets of Busbars GV2G445, GV2G454, GV2G472, with Terminal Block GV2G05

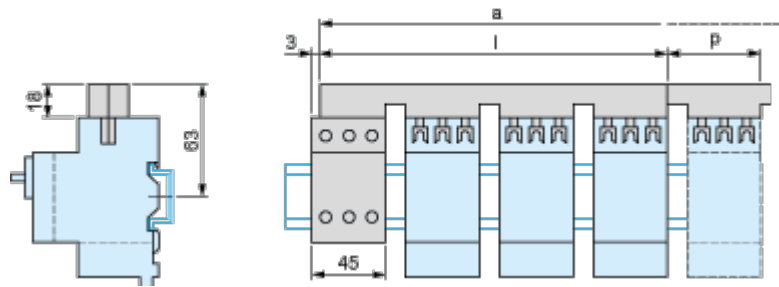

| | l | p |
|---------------------|-----|----|
| GV2G445 (4 x 45 mm) | 179 | 45 |
| GV2G454 (4 x 54 mm) | 206 | 54 |
| GV2G472 (4 x 72 mm) | 260 | 72 |

| Number of tap-offs | a | | | |
|--------------------|-----|-----|-----|-----|
| | 5 | 6 | 7 | 8 |
| GV2G445 | 224 | 269 | 314 | 359 |
| GV2G454 | 260 | 314 | 368 | 422 |
| GV2G472 | 332 | 404 | 476 | 548 |