


Product data sheet

Specifications

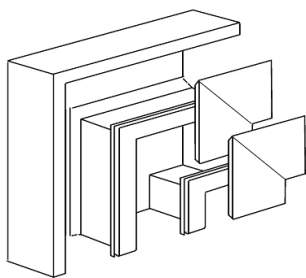

Stago - bend 90 kit, dropper - 233-2 x 72 mm - steel - white - RAL 1013

INS5558507

⚠ Discontinued on: Nov 30, 2017

⚠ End-of-service on: Dec 15, 2017

⚠ Discontinued

Main

Range Of Product	Stago
Product Or Component Type	Bend
Provided Equipment	2 x cover
Colour Tint	White (RAL 1013)
Quantity Per Set	Set of 1

Complementary

Trunking Dimension	233 x 72 mm
Compartment Partitioning	2 compartments
Operating Angle	90 °
Direction Change Type	Vertical
Front Opening Size	80 mm
Nominal Cross Section	16776 mm²
Fixing Mode	By screws By brackets
Material	Zinc coated sheet steel
Surface Finish	Powder coated
Length	250 mm
Height	233 mm
Width	72 mm

Environment

Standards	EN 50085-1:2005 EN 50085-2-1:2006
Directives	73/23/EEC - low voltage directive
Ambient Air Temperature For Operation	-20...60 °C
Ip Degree Of Protection	IP20

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	30 cm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Width	7.2 cm
Package 1 Length	30 cm
Package 1 Weight	2018 g