


Product data sheet

Specifications

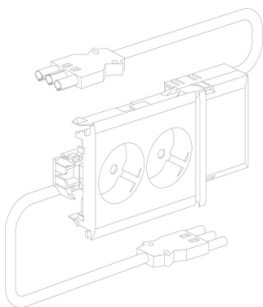

Thorsman - CYB-PS - socket outlet - double slave Wieland - 37° - white RAL 9010

INS69020

! Discontinued

! Discontinued on: Sep 26, 2017

! End-of-service on: Oct 26, 2017

Main

Range Of Product	Thorsman
Product Name	Thorsman CYB
Product Or Component Type	Socket-outlet
Device Presentation	Connection kit
Provided Equipment	Wieland male/female push-in installation coupler
Colour Tint	White (RAL 9010)
Quantity Per Set	Set of 1

Complementary

Device Composition	Protective cover End piece Strain relief
[In] Rated Current	16 A
[Ue] Rated Operational Voltage	250 V
Number Of Power Socket Outlets	2 x 2P + E with shutters, side earth
Ground Lug Position	37° ground lug
Number Of Cables	2 x 1.1 m, 3 x 2.5 mm² wire
Fixing Mode	Snap-fitted
Material	PC/ABS
Length	145 mm
Height	84 mm
Width	39 mm

Environment

Standards	IEC 60884-1
Ambient Air Temperature For Operation	-20...40 °C
Ip Degree Of Protection	IP20

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Height	3.9 cm
Package 1 Width	8.4 cm
Package 1 Length	14.5 cm
Package 1 Weight	42 g