


Product data sheet

Specifications

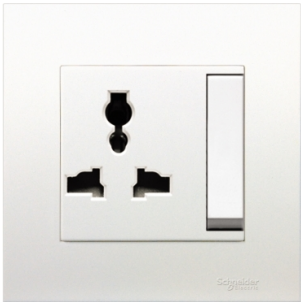

Switched Socket, Vivace, Universal, 13A, 250V, 1 gang, 3 pin, white

KB113LS

Main

Range	Vivace
Product Or Component Type	Switched socket
Device Short Name	KB113
Device Application	Power supply
Device Presentation	Complete product
Switch Application	On/off switching
Main Colour Tint	White
Colour Tint	White

Complementary

Pilot Light	Red neon indicator
Outlet Poles Configuration	2P + E
Number Of Gangs	1 gang
Colour Tint	White
Material	Polycarbonate: grid plate Polycarbonate: surround Polycarbonate: base
Projecting Depth	8 mm
Device Mounting	Flush
Mounting Support	Wall mounted
Fixing Mode	By screw M3.5
Fixing Center	60.3 mm
Embedding Depth	22.0 mm
Rated Current	13 A at 250 V AC, no inductive load
Network Frequency	50/60 Hz
Contacts Material	Brass and phosphor bronze
Connections - Terminals	Pillar terminal
Terminal Identifier	L N Earth
Tightening Torque	0.4 N.m
Clamping Connection Capacity	3 x 2.5 mm ² 2 x 4 mm ²
Width	86 mm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Height	86 mm
Depth	35 mm

Environment

Ambient Air Temperature For Operation	0...40 °C
Ambient Air Temperature For Storage	-5...60 °C
Relative Humidity	0...95 %
Operating Altitude	<= 2000 m
Environmental Characteristic	Indoor use
Ip Degree Of Protection	IP20

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Weight	117.7 g

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓ Reach Free Of Svhc

✓ Toxic Heavy Metal Free

✓ Mercury Free

✓ Rohs Exemption Information Yes

Certifications & Standards

Reach Regulation	REACH Declaration
Eu Rohs Directive	Compliant EU RoHS Declaration
China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations