


Product data sheet

Specifications

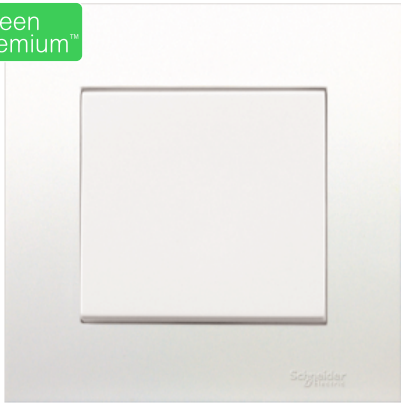

16AX 250V 1 Gang 1 Way Switch

KB31_1

Main

Range	Vivace
Product or component type	Switch
Device short name	KB31
Device application	Control
Switch function	1-way

Complementary

Device presentation	Complete mechanism
Actuator	Rocker
Number of gangs	1 gang
Colour tint	White
Material	Polycarbonate: grid plate Polycarbonate: surround Polycarbonate: base
Projecting depth	8 mm
Device mounting	Flush
Mounting support	Wall mounted
Fixing mode	By screw M3.5
Fixing center	60.3 mm
Embedding depth	35 mm
Rated current	16 AX at 250 V AC, inductive 16 AX at 250 V AC, fluorescent
[Ue] rated operational voltage	250 V AC
Network frequency	50 Hz
Contacts material	Brass and phosphor bronze
Connections - terminals	pillar terminal
Terminal identifier	L1 COM L2
Tightening torque	0.4 N.m
Clamping connection capacity	2.5 mm ²
Width	87 mm

Height	87 mm
--------	-------

Environment

Standards	MS IEC 60669-1 IEC 60669-1 SS 227
Ambient air temperature for operation	-5...40 °C
Relative humidity	0...95 %
Environmental characteristic	Indoor use

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	79.375 g

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile

Contractual warranty

Warranty	18 months
----------	-----------

Recommended replacement(s)