


Product data sheet

Specifications

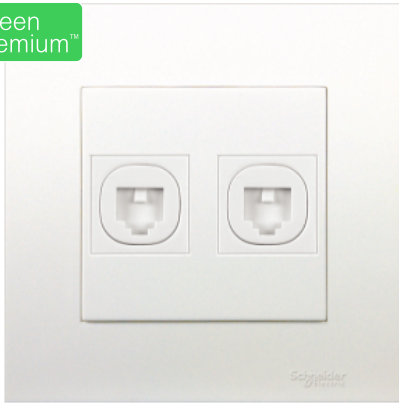

2 Gang Telephone Outlet with Shutter

KB32TS

Main

Range of product	Vivace
Range	Vivace
Device short name	KB32
Product or component type	Telephone socket
Device presentation	Complete mechanism

Complementary

Number of gangs	2 gangs
Colour tint	White
Material	Polycarbonate: surround Polycarbonate: grid plate Polycarbonate: base
Projecting depth	8 mm
Device mounting	Flush
Mounting support	Wall mounted
Fixing center	60.3 mm
Embedding depth	35 mm
Connections - terminals	Clamp terminal
Tightening torque	0.4 N.m
Width	87 mm
Height	87 mm

Environment

Ambient air temperature for operation	-5...40 °C
Relative humidity	0...95 %
Environmental characteristic	Indoor use

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1

Package 1 Height	2.2 cm
Package 1 Width	8.6 cm
Package 1 Length	8.6 cm
Package 1 Weight	90.99 g
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Height	15 cm
Package 2 Width	19 cm
Package 2 Length	10 cm
Package 2 Weight	980 g
Unit Type of Package 3	CAR
Number of Units in Package 3	100
Package 3 Height	21 cm
Package 3 Width	31.5 cm
Package 3 Length	50 cm
Package 3 Weight	9349 g

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information
Environmental Disclosure	Product Environmental Profile

Contractual warranty

Warranty	18 months
----------	-----------

Recommended replacement(s)