


Product data sheet

Specifications

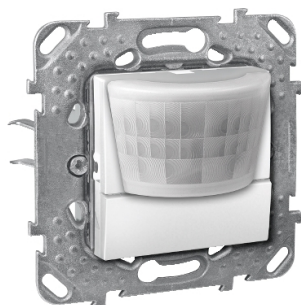

Unica KNX - movement detector - 230 VAC - 2 m - white

MGU50.533.18

⚠ Discontinued on: Dec 31, 2017

⚠ Discontinued

Main

Range	Unica
Aesthetic Name	Unica KNX
Product Or Component Type	Movement detector
Device Presentation	Mechanism with zamak fixing frame + long claws
Cover Plate Colour Tint	White

Complementary

[Ue] Rated Operational Voltage	230 V AC +/- 10 % at 50/60 Hz
Movement Detection Area	9 x 9 m(PIR mounting height 2.15m)
Detection Angle	Full 180°
Number Of Modules	2 modules
Light Intensity Adjustment	10...1000 lux rotary switch 10...2000 lux ETS
Time Delay Range	1 s...8 min (rotary switch) 1 s...255 h (ETS)
Clamping Connection Capacity	<= 2 x 2.5 mm² for flexible cable(s) <= 2 x 2.5 mm² for rigid cable(s)
Connections - Terminals	Screwless terminals
Material	ASA + PC: mechanism cover Zamak: fixing frame
Fixing Mode	Long claws
Mounting Height	1...2.5 m
Depth	56 mm
Embedding Depth	34 mm

Environment

Ip Degree Of Protection	IP20
Ambient Air Temperature For Operation	-5...45 °C
Environmental Characteristic	Acetone Bleach Petrol Liquid soap UV resistant Window-cleaning fluid Oil Alcohol

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Standards	EMC directive LV directive
-----------	-------------------------------

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	8 cm
Package 1 Width	9.5 cm
Package 1 Length	9.5 cm
Package 1 Weight	0.159 kg

Contractual warranty

Warranty	18 months
----------	-----------