


Product data sheet

Specifications

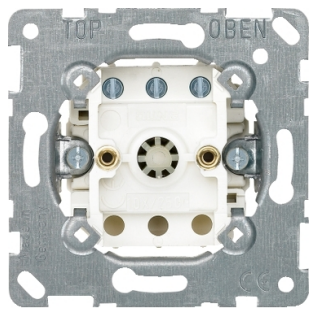

Selector switch, Merten inserts, mechanism with fixing frame, 2 positions, IP20,

MTN317100

Main

Range	Merten
Product Or Component Type	Selector switch
Device Application	Fan
Device Presentation	Mechanism with fixing frame
Technology Type	Electromechanical
Device Mounting	Flush
Actuator	Knob

Complementary

Switch Function	2 positions
[Ue] Rated Operational Voltage	250 V
Network Type	AC
Network Frequency	50/60 Hz
Fixing Mode	By screws and claws

Environment

Ip Degree Of Protection	IP20
-------------------------	------

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	6.900 cm
Package 1 Width	7.700 cm
Package 1 Length	7.900 cm
Package 1 Weight	94.000 g
Unit Type Of Package 2	CAR
Number Of Units In Package 2	40
Package 2 Height	19.900 cm
Package 2 Width	30.600 cm
Package 2 Length	40.500 cm
Package 2 Weight	4.144 kg

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)

Well-being performance

✓	Reach Free Of Svhc	
✓	Toxic Heavy Metal Free	
✓	Mercury Free	
✓	Rohs Exemption Information	Yes
Reach Regulation		REACH Declaration
Eu Rohs Directive		Compliant EU RoHS Declaration
China Rohs Regulation		China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)