


Product data sheet

Specifications

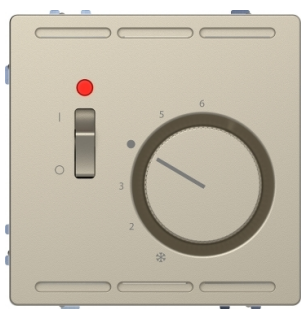

Room temperature controler 230 V with switch and cen.pl., sahara, System Design

MTN5760-6033

Main

Range	Merten
Product Name	System Design
Product Or Component Type	Thermostat
Device Presentation	Mechanism with cover plate
Colour Tint	Sahara

Complementary

Device Mounting	Flush
Fixing Mode	By screws
Device Application	Room
Technology Type	Electromechanical
Product Specific Application	Heating
Function Available	With temperature reduction With thermal feedback With bimetal sensor
Hysteresis	0.5 K
Contacts Type And Composition	1 NO
[In] Rated Current	10 A (on resistive load load) 4 A (on inductive load load) cos phi = 0.6
[Ue] Rated Operational Voltage	230 V
Network Type	AC
Network Frequency	50/60 Hz
Number Of Terminals	8 screwless terminals
Material	Thermoplastic
Ip Degree Of Protection	IP20
Height	71 mm
Width	71 mm
Depth	47 mm

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	6.0 cm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Width	7.5 cm
Package 1 Length	7.5 cm
Package 1 Weight	89.0 g
Unit Type Of Package 2	CAR
Number Of Units In Package 2	40
Package 2 Height	18.5 cm
Package 2 Width	30.0 cm
Package 2 Length	40.0 cm
Package 2 Weight	3.96 kg