


Product data sheet

Specifications

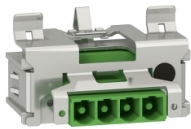

fixed connector - 4 poles - 50 A - Cellean

NSYDC4P50B

Main

Range Of Product	Cellean
Product Or Component Type	Connector
Device Short Name	NSY
Accessory / Separate Part Category	Connection accessory
Sale Per Indivisible Quantity	10.0

Complementary

Number Of Poles	4
[In] Rated Current	50 A
Material	Galvanized steel Plastic
Net Weight	0.8 kg

Environment

Standards	EN/IEC 61439-1
Product Certifications	ASEFA
Maximum Ambient Air Temperature For Operation	50 °C

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	4.500 cm
Package 1 Width	7.000 cm
Package 1 Length	7.500 cm
Package 1 Weight	97.000 g
Unit Type Of Package 2	BB1
Number Of Units In Package 2	10
Package 2 Height	6.000 cm
Package 2 Width	16.500 cm
Package 2 Length	30.000 cm
Package 2 Weight	1.069 kg
Unit Type Of Package 3	S03

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Number Of Units In Package 3	50
Package 3 Height	30.000 cm
Package 3 Width	30.000 cm
Package 3 Length	40.000 cm
Package 3 Weight	5.837 kg