


# Product data sheet

Specifications

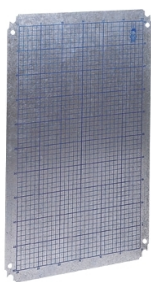

## Silkscreened plain mounting plate H800xW600mm made of galvanised sheet steel

NSYMS86

⚠ Discontinued on: Jun 30, 2023

⚠ Discontinued

### Main

Range	Spacial
Accessory / Separate Part Category	Mounting accessory
Product Or Component Type	Mounting plate
Device Application	Multi-purpose
Enclosure Nominal Dimensions	- H: 800 mm W: 600 mm - H: 600 mm W: 800 mm
Mounting Location	Step slide Direct fixing on backstuds
Mounting Plate Description	Plain
Range Compatibility	Spacial Spacial S3D Spacial Spacial CRN Spacial Spacial S3X
Quantity Per Set	Set of 1
Material	Galvanised steel
Surface Finish	Silkscreened

### Complementary

Fixing Mode	Screwed on backstuds - screw type M8 By fixing element
Permanent Permissible Load	135 kg
Height	750 mm
Width	550 mm
Depth	125 mm
Thickness	2.5 mm
Net Weight	8.059 kg
Variant Particularity	With enclosures H800 x W1200 Centimetric grid pattern

### Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	0.3 cm
Package 1 Width	55 cm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Length	75 cm
Package 1 Weight	7.742 kg
Unit Type Of Package 2	P12
Number Of Units In Package 2	60
Package 2 Height	36 cm
Package 2 Width	80 cm
Package 2 Length	120 cm
Package 2 Weight	477 kg

## Contractual warranty

Warranty	18 months
----------	-----------

## Sustainability

**Green Premium™ label** is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency   RoHS/REACH

## Well-being performance

✓ Reach Free Of Svhc

✓ Toxic Heavy Metal Free

✓ Mercury Free

✓ Rohs Exemption Information   Yes

## Certifications & Standards

Reach Regulation	<a href="#">REACH Declaration</a>
Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
China Rohs Regulation	<a href="#">China RoHS declaration</a> Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	No need of specific recycling operations